



## ELECTRICAL SPECIFICATIONS

Frequency Range: 2.4-2.48/5.15-5.85/6-7.125 GHz  
 Gain: 12/12/12 dBi  
 Polarization: Vertical and Horizontal  
 Horizontal Beamwidth: 35°/30°/30°  
 Vertical Beamwidth: 35°/30°/30°  
 VSWR: <2



## MECHANICAL SPECIFICATIONS

Dimensions: 19.3" x 19.3" x 2.44" (490x490x62mm)  
 Weight: 2.2 lb (4 kg)  
 Installation: Flush Mount to Wall or Articulating Mount  
 (included)

Radome Material: ASA  
 Connector: N-Style  
 Number of Leads: 8  
 Cable Length: 36" (910mm)  
 Cable Type: ATS-195



## ENVIRONMENTAL SPECIFICATIONS


Installation Environment: Indoor/Outdoor  
 IP Rating: IP66

## WARRANTY

2 Year Limited Warranty



## HORIZONTAL

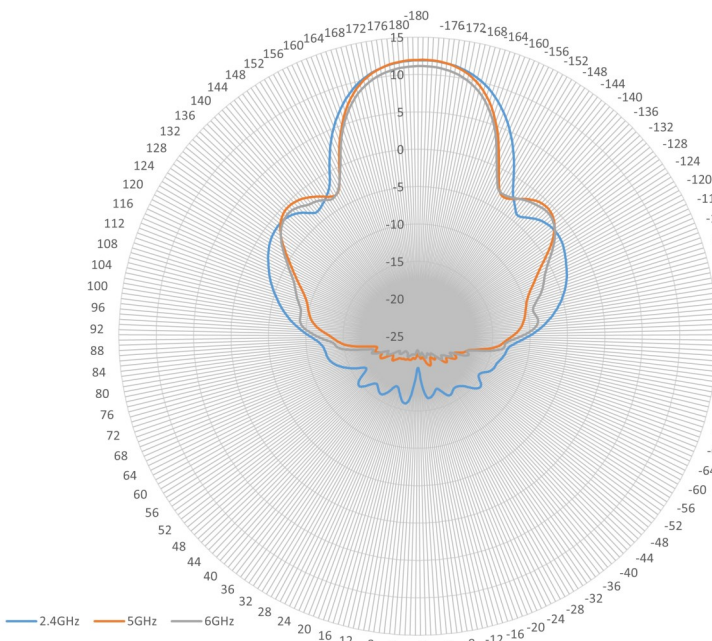

## VERTICAL

