



ELECTRICAL SPECIFICATIONS

Frequency Range: 2.4-2.48/5.15-5.85/6-7.125 GHz
 Gain: 13/15/15 dBi
 Polarization: 3 Vertical / 3 Horizontal
 Horizontal Beamwidth: 25/20/20°
 Vertical Beamwidth: 25/20/20°
 VSWR: <1.5:1 Max: 2.0
 Isolation: >30dB
 Impedance: 50 Ω



MECHANICAL SPECIFICATIONS

Dimensions: 24"x24"x1.6" (600x600x40mm)
 Weight: 2.5 lb (0.68 kg)
 Installation: Flush Mount to Wall or Articulating
 Wall/Pole Mount (included)

Radome Material: ABS
 Connector: RPSMA Plug
 Number of Leads: 6
 Cable Length: 36" (910mm)
 Cable Type: ATS-195



ENVIRONMENTAL SPECIFICATIONS


Installation Environment: Indoor/Outdoor
 IP Rating: IP67

WARRANTY

2 Year Limited Warranty



VERTICAL

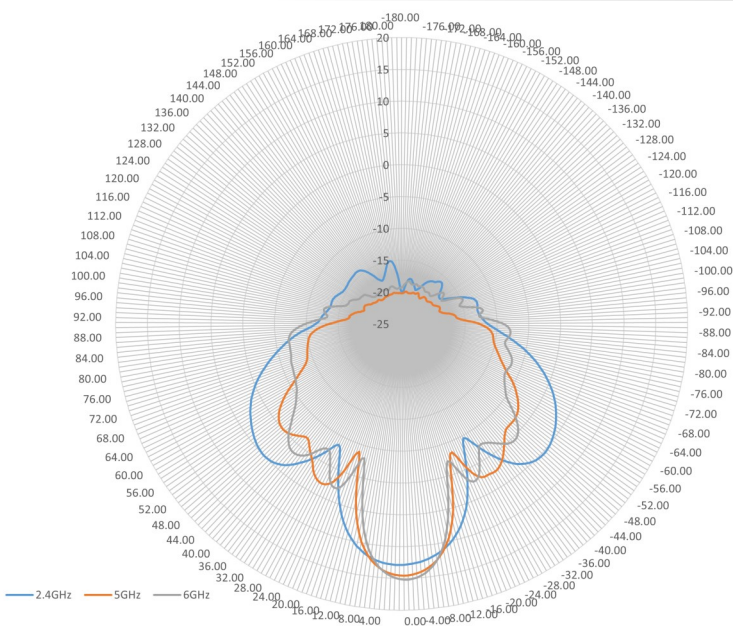

HORIZONTAL

