



ELECTRICAL SPECIFICATIONS

Frequency Range: 2.4-2.485/5.15-5.85 GHz
Gain: 13 dBi
Polarization: Horizontal
Horizontal Beamwidth: 22°/13°
Vertical Beamwidth: 97°/84°

VSWR: $\leq 1.5:1$, max 2.0
Isolation: >30 dB
Impedance: 50 Ω
Lightning Protection: None
Max Input Power: 50 W per port



MECHANICAL SPECIFICATIONS

Dimensions: 11.81" x 11.81" x 1.57" (300 x 300 x 40mm)
Weight: 2.5 lb (1.13 kg)
Installation: Flush Mount to Wall or Articulating wall/Pole Mount (included)

Radome Material: ABS
Connector: RPSMA Plug
Number of Leads: 5
Cable Length: 36" (910mm)
Cable Type: RG402 Plenum



ENVIRONMENTAL SPECIFICATIONS


Installation Environment: Indoor/Outdoor
Operating Temperature: -40 to 158°F (-40 to 70°C)
Wind Velocity: 134 mph (216 km/h)
IP Rating: IP66

WARRANTY

2 Year Limited Warranty



2.4 GHZ

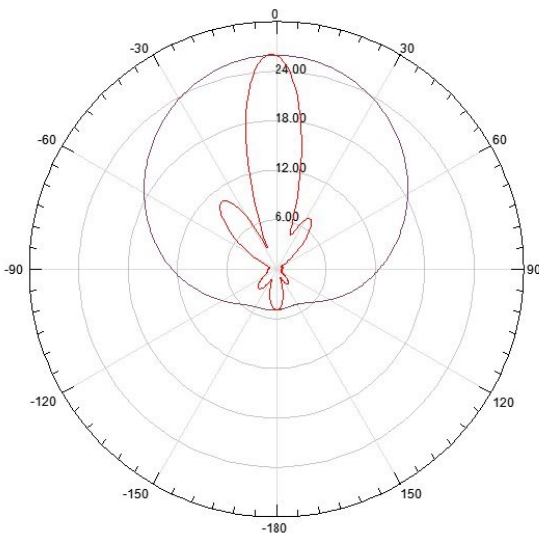

5.5 GHZ

