



## ELECTRICAL SPECIFICATIONS

Frequency Range: 2.4-2.5/4.9-5.85 GHz  
Gain: 4 / 7 dBi  
Polarization: Vertical  
Horizontal Beamwidth: 99°/58°  
Vertical Beamwidth: 65°/40°

VSWR: < 2.0:1  
Isolation: > 20dB  
Impedance: 50Ω  
Lightning Protection: DC Grounded  
Max Input Power: 100W



## MECHANICAL SPECIFICATIONS

Dimensions: 5.5" x 4.7" x 1.5" (140x120x39mm)  
Weight: 0.9 lb (0.4 kg)  
Mounting: Threaded Bolt w/ Nut  
& Articulating Wall/Pole Mount (included)  
Installation Hole Diameter: 1" (25mm)  
Pole Mount Diameter: 2" (50mm)

Radome Material: ASA  
Connector: N-Style  
Number of Leads: 4  
Cable Length: 36" (910 mm)  
Cable Type: RG58



## ENVIRONMENTAL SPECIFICATIONS

Installation Environment: Indoor/Outdoor  
Operating Temperature: -40 to 149°F (-40 to 65°C)  
Wind Velocity: 130 mph (209 km/h)  
IP Rating: IP66


## WARRANTY

2 Year Limited Warranty




## 2.5 GHZ


## 5 GHZ

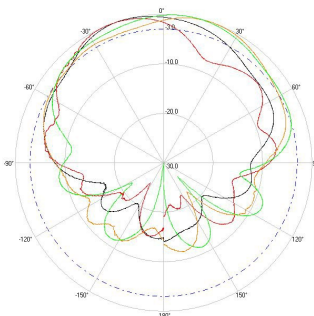


H-Plane

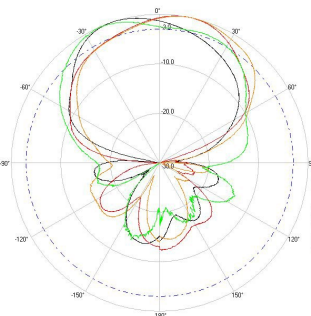

V-Plane

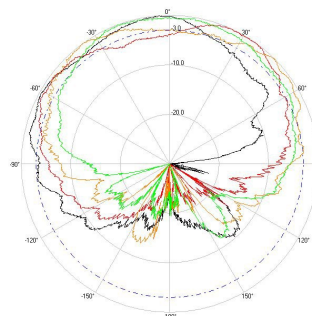

H-Plane

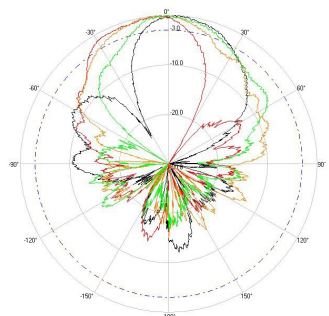

V-Plane