



## ELECTRICAL SPECIFICATIONS

Frequency Range: 2.4-2.485/5.15-5.85 GHz  
 Gain: 7 dBi  
 Polarization: 3 Vertical, 3 Horizontal  
 Horizontal Beamwidth: 66°/65°  
 Vertical Beamwidth: 66°/62°  
 VSWR: ≤1.5:1, max 2.0  
 Isolation: >30 dB  
 Impedance: 50 Ω



## MECHANICAL SPECIFICATIONS

Dimensions: 12.2" x 8.66" x 1.57" (310x220x40mm)  
 Weight: 1.5 lb (0.68 kg)  
 Installation: Flush Mount to Wall OR included Articulating Mount (included)

Radome Material: ABS  
 Connector: N-Style Plug  
 Number of Leads: 6  
 Cable Length: 36" (910mm)  
 Cable Type: RG402 Plenum



## ENVIRONMENTAL SPECIFICATIONS


Installation Environment: Indoor/Outdoor  
 Operating Temperature: -40 to 158°F (-40 to 70°C)  
 Wind Velocity: 134 mph (216 km/h)  
 IP Rating: IP66

## WARRANTY

2 Year Limited Warranty



## HORIZONTAL

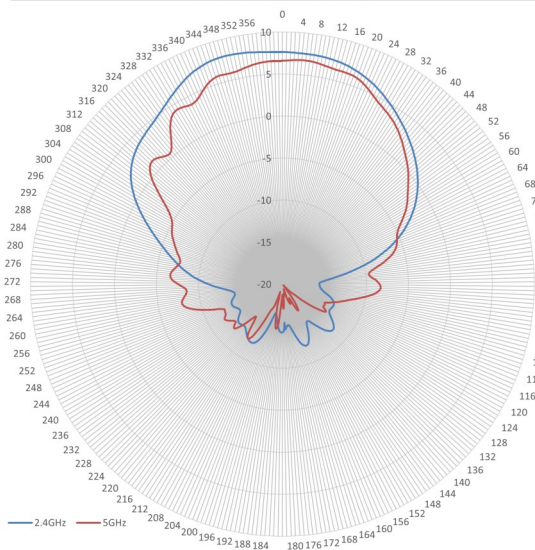

## VERTICAL

