



## ELECTRICAL SPECIFICATIONS

Frequency Range: 2.4-2.5 / 5.1-5.85 GHz  
 Gain: 8 dBi  
 Polarization: 3 Vertical, 3 Horizontal  
 Horizontal Beamwidth: 100° / 100°  
 Vertical Beamwidth: 40° / 25°  
 VSWR: <1.5  
 Impedance: 50 Ω

## MECHANICAL SPECIFICATIONS

Dimensions: 12.6" x 10.3" x 1.4" (320mm x 260mm x 35mm)  
 Radome Material: ABS  
 Mounting: Flush Mount to Wall OR Articulating Mount (included)

Cable Length: 36" (910mm)  
 Cable Type: ATS-195  
 Connector: N-Style Plug  
 Number of Leads: 6

## ENVIRONMENTAL SPECIFICATIONS


Installation Environment: Indoor/Outdoor  
 IP Rating: IP66

## WARRANTY


2 Year Limited Warranty

## 2.4 GHZ


## 5 GHZ

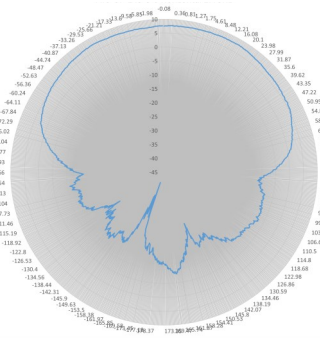


Horizontal

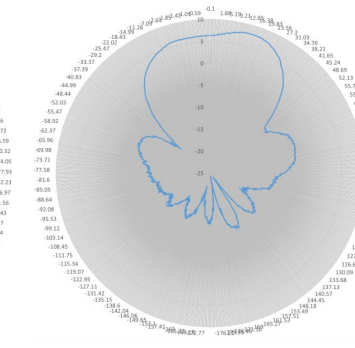

Vertical

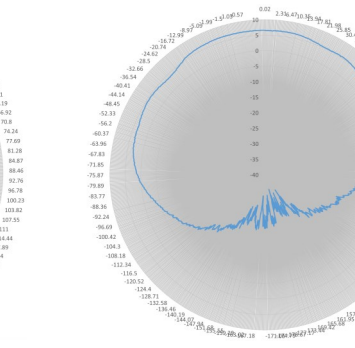

Horizontal

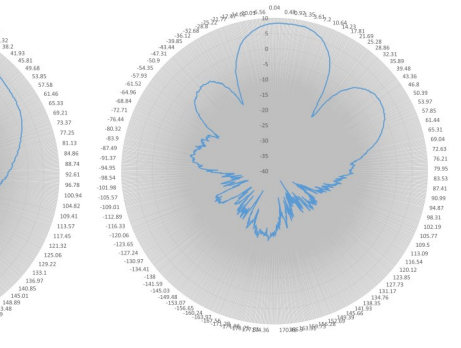

Vertical