



2.4/5 GHZ 8/10/10 DBI 4 ELEMENT INDOOR/OUTDOOR PATCH ANTENNA WITH N-STYLE ATS-OP-2456-81010-4NP-36



ELECTRICAL SPECIFICATIONS

Frequency Range: 2.4-2.48/5.15-5.85/6-7.125 GHz
Gain: 8/10/10 dBi
Polarization: 2 Vertical / 2 Horizontal
Horizontal Beamwidth: 60°/50°/40°
Vertical Beamwidth: 60°/50°/40°
VSWR: <1.5:1 Max: 2.0

Isolation: >30dB
Impedance: 50Ω



MECHANICAL SPECIFICATIONS

Dimensions: 11.81" x 11.81" x 1.85" (300x300x39mm)
Weight: 2.5 lbs. (1.13 kg)
Installation: Flush Mount to Wall or Articulating
Wall/Pole Mount (included)

Radome Material: ABS
Connector: N-Style Plug
Number of Leads: 4
Cable Length: 36" (914.4mm)
Cable Type: ATS-195



ENVIRONMENTAL SPECIFICATIONS

Installation Environment: Indoor/Outdoor
IP Rating: IP67



WARRANTY

2 Year Limited Warranty



HORIZONTAL

VERTICAL

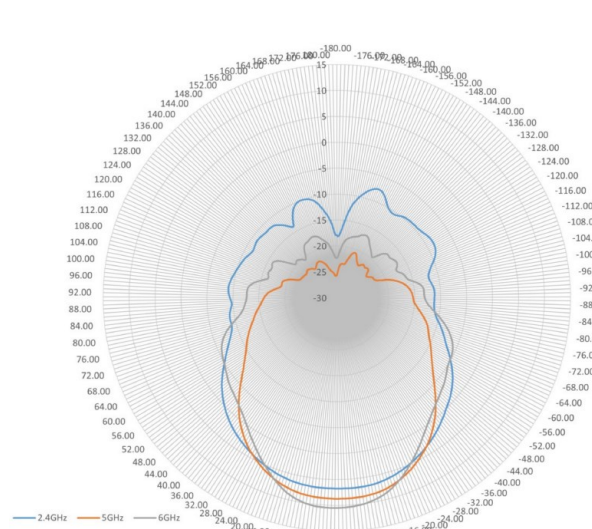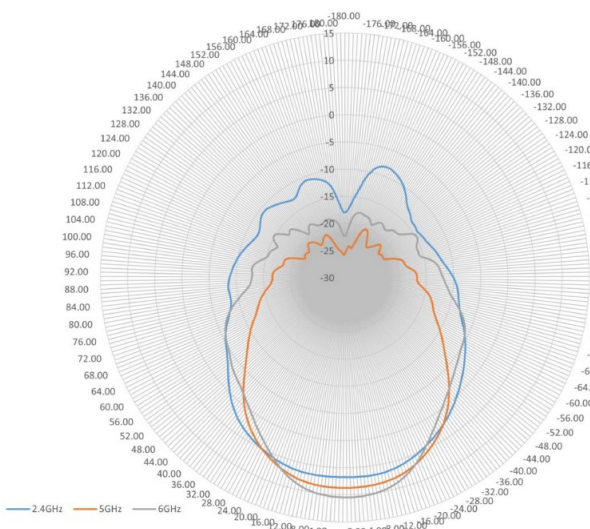



2.4/5/6 GHZ 8/10/10 DBI 4 ELEMENT INDOOR/ OUTDOOR PATCH ANTENNA WITH N-STYLE ATS-OP-2456-81010-4NP-36

