



# 2.4/5 GHZ 8/10/10 DBI 4 ELEMENT INDOOR/OUTDOOR PATCH ANTENNA WITH RPSMA ATS-OP-2456-81010-4RPSP-36



## ELECTRICAL SPECIFICATIONS

Frequency Range: 2.4-2.48/5.15-5.85/6-7.125 GHz  
Gain: 8/10/10 dBi  
Polarization: 2 Vertical / 2 Horizontal  
Horizontal Beamwidth: 60°/50°/40°  
Vertical Beamwidth: 60°/50°/40°  
VSWR: <1.5:1 Max: 2.0

Isolation: >30dB  
Impedance: 50Ω



## MECHANICAL SPECIFICATIONS

Dimensions: 11.81" x 11.81" x 1.85" (300x300x39mm)  
Weight: 2.5 lbs. (1.13 kg)  
Installation: Flush Mount to Wall or Articulating  
Wall/Pole Mount (included)

Radome Material: ABS  
Connector: RPSMA Plug  
Number of Leads: 4  
Cable Length: 36" (914.4mm)  
Cable Type: ATS-195



## ENVIRONMENTAL SPECIFICATIONS

Installation Environment: Indoor/Outdoor  
IP Rating: IP67



## WARRANTY

2 Year Limited Warranty



## HORIZONTAL

## VERTICAL

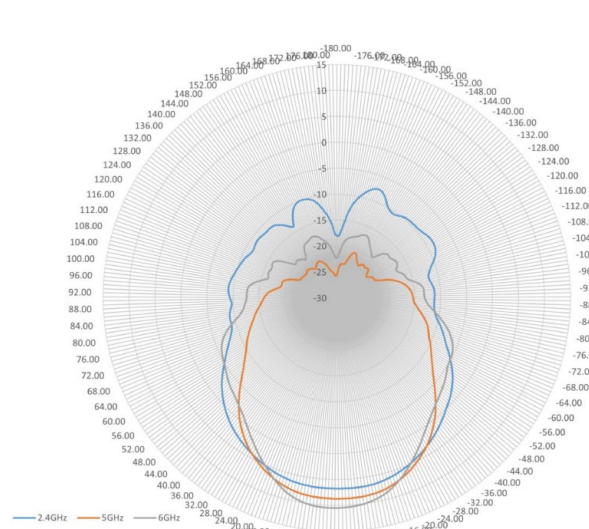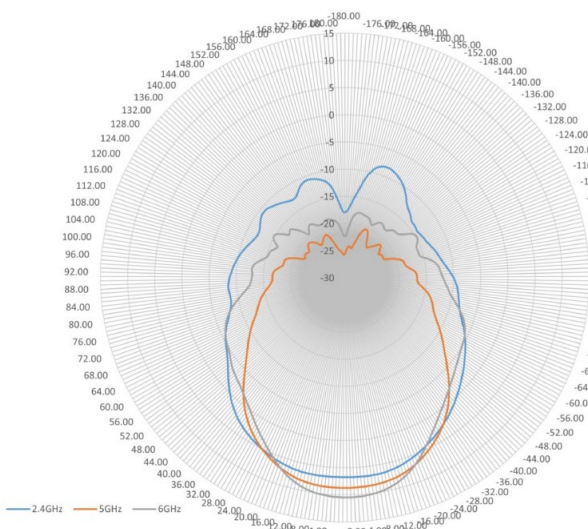



# 2.4/5/6 GHZ 8/10/10 DBI 4 ELEMENT INDOOR/ OUTDOOR PATCH ANTENNA WITH RPSMA ATS-OP-2456-81010-4RPSP-36

