



ELECTRICAL SPECIFICATIONS

Frequency Range: 698-960/1710-2690/3300-3800MHz
 Gain: 6/9/8 dBi
 Polarization: Horizontal
 Horizontal Beamwidth: 75°/50°/60°
 Vertical Beamwidth: 75°/50°/60°
 VSWR: <2.0



MECHANICAL SPECIFICATIONS

Dimensions: 10"x 9"x3.5" (254x228.6x88.9mm)
 Weight: 2.2 lbs. (1 kg)
 Installation: Flush Mount to Wall OR included Articulating Mount

Radome Material: ABS
 Connector: SMA
 Number of Leads: 2
 Cable Length: 36" (910mm)
 Cable Type: ATS-200



ENVIRONMENTAL SPECIFICATIONS


Installation Environment: Indoor/Outdoor
 Operating Temperature: -40 to 158°F (-40 to 70°C)
 Wind Velocity: 134 mph (216 km/h)
 IP Rating: IP66

WARRANTY

2 Year Limited Warranty



HORIZONTAL

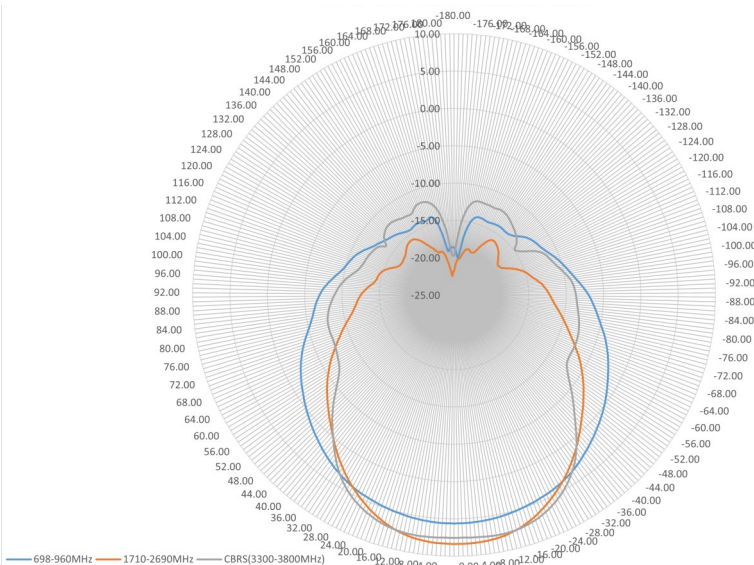

VERTICAL

