




# Plant Paging Station

By Austdac  
Catalog # 810-350D100

ICS SmartSeries Indoor Speaker Amplifier Station - 100-240VAC  
- UL Class I, Div 2 - 8-ohm speaker output with SmartVolume -  
SmartSeries features with RTU input/output - Orange finish

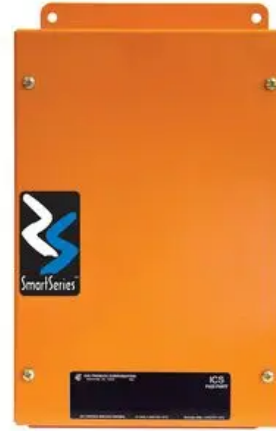

## General

Catalog Number	810-350D100
Color	Orange
Material	Steel
Output Level Speaker	8 Ohm
Power	30 W
Series	ICS
Signal Type	Analog
Type	<ul style="list-style-type: none"><li>• Speaker Amplifier Station</li><li>• Indoor Speaker Amplifier Stations</li></ul>
Weather Rating	NEMA Type 12

## Dimensions

Cubic Capacity	610.90965 cu.in
Depth	5.07 in

Height	14.5 in
Weight	11 lb
Width	8.31 in

## Electrical Ratings

Input Voltage	100-240 VAC
Signal	33 Ohm
Voltage Rating	100-240 VAC

## Certifications And Compliance

Certified Listed	UL
Hazardous Rating(s)	UL Div 2

## Product Assets

[Installation Manuals - ICS Class I, Div. 2 Page/Party® Station Literature - ICS Amplifiers](#)