


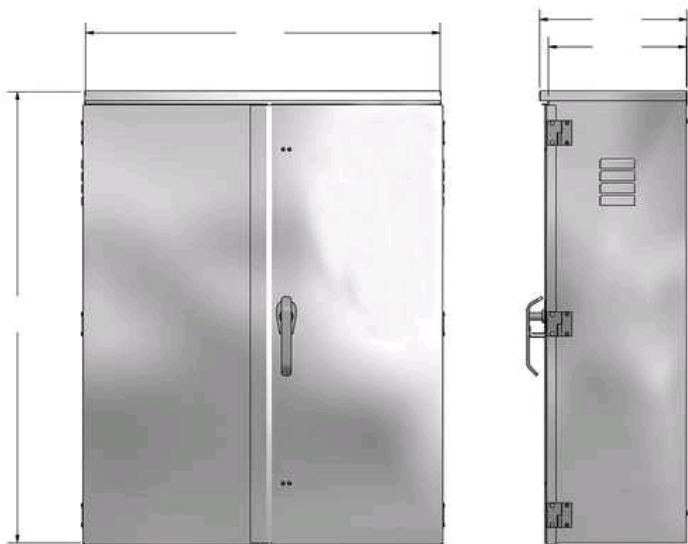

BA123238DD

by CMC
Catalog ID: BA123238DD

Outdoor Meter, Instrument Transfer & Substation
Equipment Enclosures, NEMA 3R, Board Size 29" x 35"

- Mounting Board is 3/4" exterior grade treated plywood in standard. Add "-AP" for aluminum back-plate at extra charge
- Standard double swinging doors with stainless steel lift-off hinges, 3-point locking handle. Doors have brackets, which hold them in the open position
- HUBS provided when requested at extra charge
- 4" louvers with screens (standard)
- Ground lug is Al-Cu lug furnished (standard).

Special sizes and modifications available upon request.

Product Details

General

Material	Aluminum
UPC	192663141579

Dimensions

Cubic Capacity	14592 cu.in
Depth	12 in
Height	38 in
Width	32 in

