


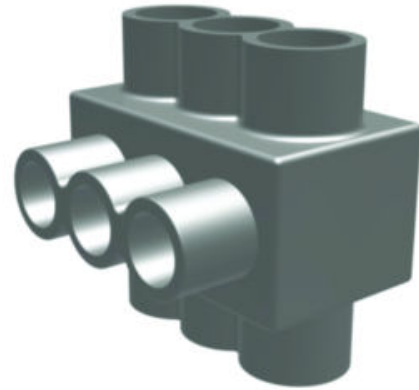

1PLD2504, UV Rated Black, 2-sided, 4-ports, #10 AWG-250 kcmil

By Burndy
Catalog # [1PLD2504](#)

Al Distribution Tap Connectors, UV Black Plastisol Covered, 4 Ports, Double Sided Entry, #10-250 kcmil, 600 V, Torque 275 in/lbs, Temp Rating 90 Deg C.



Features

- UV Rated Covering over AL6061-T6 aluminum body saves time, lowering installation costs and eliminates taping
- Oxide inhibitor pre-installed inhibits moisture and contaminants from entering the contact area
- Range-taking capability reduces the number of connectors necessary to carry in inventory

Application

For Indoor Use Only, Copper Or Stranded Aluminum

General

Catalog Number	1PLD2504
Connector Type	Multi Tap
EU RoHS Indicator	Yes
Hex Key	5/16
Installation Torque Recommended in-lb	275 in-lb
Insulation	Y
Insulation Type	Plastisol
Material	Aluminum
Material - Hardware	Aluminum
Number Of Ports	4
Physical Attribute - Number of Screws	4
Physical Attribute - Screw Type	Allen
Plated	N
Plating Type	Unplated
Sub Brand	UNITAP
Temperature Rating	194° F
Trade Name	UNITAP™
Type	BIBD, Multi-Port
UPC	781810287194
UPC 12 Digit	7818102871944

Dimensions

Dimension - Height fraction	2.125 in
Dimension - Height inch	2.13 in
Dimension - L Length Overall mm	99 mm
Dimension - Length Overall inch	3.91 in
Dimension - Screw Size inch	5/8
Dimension - Width fraction	2-16/25 in

Conductor Related

Conductor - AL Str Size	10 AWG;9 AWG;8 AWG;7 AWG;6 AWG;5 AWG;4 AWG;3 AWG;2 AWG;1 AWG;1/0 ;2/0 AWG;3/0 AWG;4/0 AWG;250 kcmil
Conductor - AL Str Size Range	10 AWG - 250 kcmil
Conductor - Copper Str Size	10 AWG;9 AWG;8 AWG;7 AWG;6 AWG;5 AWG;4 AWG;3 AWG;2 AWG;1 AWG;1/0 ;2/0 AWG;3/0 AWG;4/0 AWG;250 kcmil
Conductor - Copper Str Size Range	10 AWG - 250 kcmil
Conductor Size	10 AWG-250 KCMIL
Conductor Type	<ul style="list-style-type: none">• AL C Str-Size• CU C Str-Size

Certifications And Compliance

Certification - CSA Approved	No
Certification - ETL	No
Certification - UL Listed Direct Burial	No
Certification - UL Recognized	No
Certification - cULus	No
Standards - RoHS Compliance Status	CM
UL Listed	Yes

Logistics

Minimum Pack Quantity	1
-----------------------	---

Product Assets

[Catalogs - UNITAP™ Products](#)
[Catalogs - Full Line BURNDY Catalog](#)
[Catalogs - Section A - Mechanical](#)
[Customer Notices - Prop 65 Notice](#)
[Product Cross Section Image\(s\) - BUR_PLD_LineArt](#)
[Sales Drawings - SD214514-04](#)

Dimension - Width inch 2.64 in
Dimension - Width mm 67 mm

Electrical Ratings

Voltage - Maximum 600 V



A proud member of the Hubbell Family.

©2024 Hubbell Incorporated. All rights reserved.
BRDY-IPLD2504-SPEC-EN | REV 6/2024