




# 1PLD6006, UV Rated Black, 2-sided, 6-ports, #4 AWG - 600 kcmil

By Burndy  
Catalog # 1PLD6006

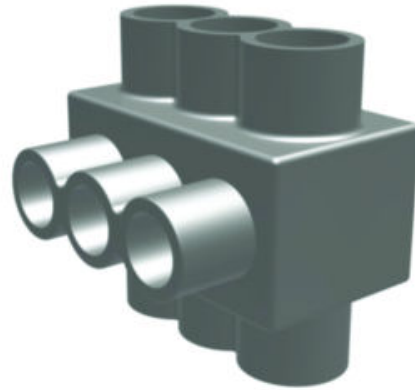

Al Distribution Tap Connectors, UV Black Plastisol Covered, 6 Ports, Double Sided Entry, #4-600 kcmil, 600 V, Torque 375 in/lbs, Temp Rating 90 Deg C.

## Features

- UV Rated Covering over AL6061-T6 aluminum body saves time, lowering installation costs and eliminates taping
- Oxide inhibitor pre-installed inhibits moisture and contaminants from entering the contact area
- Range-taking capability reduces the number of connectors necessary to carry in inventory

## Application

For Indoor Use Only, Copper Or Stranded Aluminum

## General

Catalog Number	1PLD6006
Connector Type	Multi Tap
EU RoHS Indicator	Yes
Hex Key	3/8
Installation Torque Recommended in-lb	375 LBS/in
Insulation	Y
Insulation Type	Plastisol
Material	Aluminum
Material - Hardware	Aluminum
Number Of Ports	6
Physical Attribute - Number of Screws	6
Physical Attribute - Screw Type	Allen
Plated	N
Plating Type	Unplated
Sub Brand	UNITAP
Temperature Rating	194
Trade Name	UNITAP™
Type	BIBD, Multi-Port
UPC	781810287378
UPC 12 Digit	7818102873788

## Dimensions

Dimension - Height fraction	2.75 in
Dimension - Height inch	2.75 in
Dimension - L Length Overall mm	199 mm
Dimension - Length Overall inch	7.84 in
Dimension - Screw Size inch	13/16
Dimension - Width inch	3.00 in

## Conductor Related

Conductor - AL Str Size	4 AWG;3 AWG;2 AWG;1 AWG;1/0 AWG;2/0 AWG;3/0 AWG;4/0 AWG;250 kcmil;266 kcmil;300 kcmil;336 kcmil;350 kcmil;397 kcmil;400 kcmil;450 kcmil;477 kcmil;500 kcmil;550 kcmil;556 kcmil;600 kcmil
Conductor - AL Str Size Range	4 AWG - 600 kcmil
Conductor - Copper Str Size	4 AWG;3 AWG;2 AWG;1 AWG;1/0 ;2/0 AWG;3/0 AWG;4/0 AWG;250 kcmil;300 kcmil;350 kcmil;400 kcmil;450 kcmil;500 kcmil;550 kcmil;600 kcmil
Conductor - Copper Str Size Range	4 AWG - 600 kcmil
Conductor Size	4 AWG-600 KCMIL
Conductor Type	<ul style="list-style-type: none"><li>• AL C Str-Size</li><li>• CU C Str-Size</li></ul>

## Certifications And Compliance

Certification - CSA Approved	No
Certification - ETL	No
Certification - UL Listed Direct Burial	No
Certification - UL Recognized	No
Certification - cULus	No
Standards - RoHS Compliance Status	CM
UL Listed	Yes

## Logistics

Minimum Pack Quantity	1
-----------------------	---

## Product Assets

[Catalogs - UNITAP™ Products](#)  
[Catalogs - Full Line BURNDY Catalog](#)  
[Catalogs - Section A - Mechanical](#)  
[Customer Notices - Prop 65 Notice](#)  
[Product Cross Section Image\(s\) - BUR\\_PLD\\_LineArt](#)  
[Sales Drawings - SD214514-06](#)

Dimension - Width mm 76 mm

## Electrical Ratings

Voltage - Maximum 600 V



A proud member of the Hubbell Family.

©2024 Hubbell Incorporated. All rights reserved.  
BRDY-1PLD6006-SPEC-EN | REV 6/2024