




# 1PLM2504, UV Rated Black, Mount Tap, 1-side, 4-port

By Burndy  
Catalog # [1PLM2504](#)

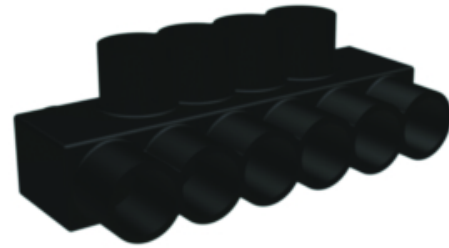

Mounted Block Tap Connector, 4 Ports, Single Side Entry, 5.53 IN L.

## General

Connector Type	Multi Tap
Installation Torque Recommended in-lb	275 in-lb
Insulation	Y
Insulation Type	Plastisol
Material	Aluminum
Number Of Ports	4
Physical Attribute - Number of Screws	6
Plated	Y
Plating Type	Clear Plated
Temperature Rating	194° F
Trade Name	UNITAP™
UPC	781810307946
UPC 12 Digit	7818103079466

## Dimensions

Dimension - Height fraction	2-5/8 in
Dimension - Height inch	2.62 in
Dimension - L Length Overall mm	140
Dimension - Length Overall inch	5.53
Dimension - Width inch	2.07
Dimension - Width mm	53 mm

## Electrical Ratings

Voltage - Maximum	600 V
-------------------	-------

## Conductor Related

Conductor - AL Str Size	10 AWG;9 AWG;8 AWG;7 AWG;6 AWG;5 AWG;4 AWG;3 AWG;2 AWG;1 AWG;1/0 ;2/0 AWG;3/0 AWG;4/0 AWG;250 kcmil
Conductor - AL Str Size Range	10 AWG-250 kcmil
Conductor - Copper Str Size	10 AWG;9 AWG;8 AWG;7 AWG;6 AWG;5 AWG;4 AWG;3 AWG;2 AWG;1 AWG;1/0 ;2/0 AWG;3/0 AWG;4/0 AWG;250 kcmil
Conductor - Copper Str Size Range	10 AWG-250 kcmil
Conductor Size	10 AWG-250 KCMIL
Conductor Type	<ul style="list-style-type: none"><li>AL C Str-Size</li><li>CU C Str-Size</li></ul>

## Certifications and Compliance

Certification - CSA Approved	Yes
Certification - ETL	No
Certification - UL Listed Direct Burial	No
Certification - UL Recognized	No
Certification - cULus	No
Standards - RoHS Compliance Status	CM
UL Listed	Yes

## Logistics

Minimum Pack Quantity	100
-----------------------	-----

## Product Assets

[Catalogs - UNITAP™ Products](#)  
[Customer Notices - Prop 65 Notice](#)  
[Sales Drawings - 50015427](#)



A proud member of the Hubbell Family.

©2024 Hubbell Incorporated. All rights reserved.  
BRDY-1PLM2504-SPEC-EN | REV 1/2024

