




## **1PLM60012, UV Rated Black, Mount Tap, 1-side, 12-port**

By Burndy  
Catalog # [1PLM60012](#)

Mounted Block Tap Connector, 12 Ports, Single Side Entry, 17.84  
IN L.

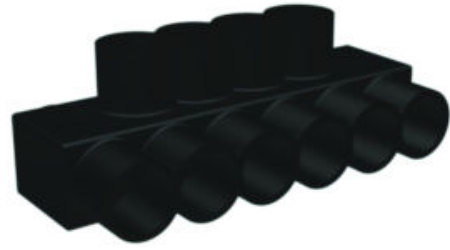

## Features

- UV Rated Covering over AL6061-T6 aluminum body saves time, lowering installation costs and eliminates taping
- Oxide inhibitor pre-installed inhibits moisture and contaminants from entering the contact area
- Range-taking capability reduces the number of connectors necessary to carry in inventory

## General

Catalog Number	1PLM60012
Connector Type	Multi Tap
Installation Torque	375 in-lb
Recommended in-lb	
Insulation	Y
Insulation Type	Plastisol
Material	Aluminum
Material - Hardware	Aluminum
Number Of Ports	12
Physical Attribute - Number of Screws	14
Plated	Y
Plating Type	Clear Plated
Temperature Rating	194° F
Trade Name	UNITAP™
UPC	781810308035
UPC 12 Digit	7818103080355

## Dimensions

Dimension - Height fraction	2-7/8 in
Dimension - Height inch	2.88
Dimension - L Length Overall mm	453
Dimension - Length Overall inch	17.84
Dimension - Width inch	2.38
Dimension - Width mm	60 mm

## Electrical Ratings

Voltage - Maximum	600 V
-------------------	-------

## Conductor Related

Conductor - AL Str Size	4 AWG;3 AWG;2 AWG;1 AWG;1/0 AWG;2/0 AWG;3/0 AWG;4/0 AWG;250 kcmil;266 kcmil;300 kcmil;336 kcmil;350 kcmil;397 kcmil;400 kcmil;450 kcmil;477 kcmil;500 kcmil;550 kcmil;556 kcmil;600 kcmil
Conductor - AL Str Size Range	4 AWG - 600 kcmil
Conductor - Copper Str Size	4 AWG;3 AWG;2 AWG;1 AWG;1/0 AWG;2/0 AWG;3/0 AWG;4/0 AWG;250 kcmil;266 kcmil;300 kcmil;336 kcmil;350 kcmil;397 kcmil;400 kcmil;450 kcmil;477 kcmil;500 kcmil;550 kcmil;556 kcmil;600 kcmil
Conductor - Copper Str Size Range	4 AWG - 600 kcmil
Conductor Size	4 AWG-600 KCMIL
Conductor Type	<ul style="list-style-type: none"><li>• AL C Str-Size</li><li>• CU C Str-Size</li></ul>

## Certifications And Compliance

Certification - CSA Approved	Yes
Certification - ETL	No
Certification - UL Listed Direct Burial	No
Certification - UL Recognized	No
Certification - cULus	No
Standards - RoHS Compliance Status	CM
UL Listed	Yes

## Logistics

Minimum Pack Quantity	1
-----------------------	---

## Product Assets

[Catalogs - UNITAP™ Products](#)  
[Catalogs - BURNDY Master Catalog - Full Line BURNDY Catalog](#)  
[Interactive Catalog - BURNDY Full-Line Digital Catalog](#)  
[Product Cross Section Image\(s\) - BUR\\_PLM\\_LineArt](#)  
[Sales Drawings - 50015514](#)  
[Specifications - 1PLM60012](#)



A Hubbell brand

©2024 Hubbell Incorporated. All rights reserved  
BRDY-1PLM60012-SPEC-EN | REV 8/2024