




1PLM6004, UV Rated Black, Mount Tap, 1-side, 4-port

By Burndy
Catalog # [1PLM6004](#)

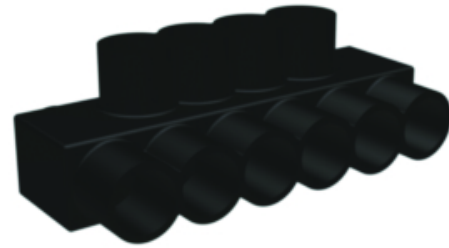

Mounted Block Tap Connector, 4 Ports, Single Side Entry, 7.59 IN L.

General

Connector Type	UV Rated Black UNITAP
Installation Torque Recommended in-lb	375 in-lb
Insulation	Y
Insulation Type	Plastisol
Material	Aluminum
Material - Hardware	Aluminum
Number Of Ports	4
Physical Attribute - Number of Screws	6
Plated	Y
Plating Type	Clear Plated
Temperature Rating	194° F
Trade Name	UNITAP™
UPC	781810308042
UPC 12 Digit	7818103080422

Dimensions

Dimension - Height fraction	2-7/8 in
Dimension - Height inch	2.88
Dimension - L Length Overall mm	193
Dimension - Length Overall inch	7.59
Dimension - Width inch	2.38
Dimension - Width mm	60 mm

Electrical Ratings

Voltage - Maximum	600 V
-------------------	-------

Conductor Related

Conductor - AL Str Size	4 AWG;3 AWG;2 AWG;1 AWG;1/0 AWG;2/0 AWG;3/0 AWG;4/0 AWG;250 kcmil;266 kcmil;300 kcmil;336 kcmil;350 kcmil;397 kcmil;400 kcmil;450 kcmil;477 kcmil;500 kcmil;550 kcmil;556 kcmil;600 kcmil
Conductor - AL Str Size Range	4 AWG-600 kcmil
Conductor - Copper Str Size	4 AWG;3 AWG;2 AWG;1 AWG;1/0 AWG;2/0 AWG;3/0 AWG;4/0 AWG;250 kcmil;266 kcmil;300 kcmil;336 kcmil;350 kcmil;397 kcmil;400 kcmil;450 kcmil;477 kcmil;500 kcmil;550 kcmil;556 kcmil;600 kcmil
Conductor - Copper Str Size Range	4 AWG-600 kcmil
Conductor Size	4 AWG-600 KCMIL
Conductor Type	<ul style="list-style-type: none">AL C Str-SizeCU C Str-Size

Certifications and Compliance

Certification - CSA Approved	Yes
Certification - ETL	No
Certification - UL Listed Direct Burial	No
Certification - UL Recognized	No
Certification - cULus	No
Standards - RoHS Compliance Status	CM
UL Listed	Yes

Logistics

Minimum Pack Quantity	1
-----------------------	---

Product Assets

[Catalogs - UNITAP™ Products](#)
[Customer Notices - Prop 65 Notice](#)
[Sales Drawings - 50015514](#)



A proud member of the Hubbell Family.

©2024 Hubbell Incorporated. All rights reserved.
BRDY-1PLM6004-SPEC-EN | REV 1/2024

