




# 1PLMD25012, UV Rated Black, Mount Tap, 2-sided, 12-port, #10 AWG-250 kcmil

By Burndy  
Catalog # 1PLMD25012

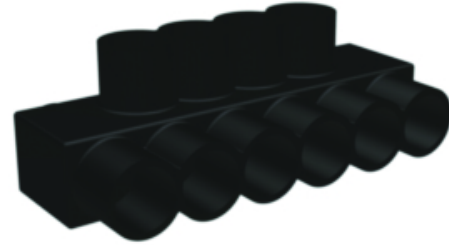

Mounted Black Tap Connector, 12 Ports, Double Side Entry,  
#10-250 kcmil, 13.03 IN L, 2.64 IN W.

## General

Connector Type	Multi Tap
Hex Key	5/16
Insulation	Y
Insulation Type	Plastisol
Material	Aluminum
Material - Hardware	Aluminum
Number Of Ports	12
Physical Attribute - Number of Screws	14
Plated	N
Plating Type	Unplated
Temperature Rating	194° F
Trade Name	UNITAP™
UPC	781810307571
UPC 12 Digit	7818103075711

## Dimensions

Dimension - Height fraction	2-1/4 in
Dimension - Height inch	2.13
Dimension - L Length Overall mm	331
Dimension - Length Overall inch	13.03
Dimension - Width inch	2.64
Dimension - Width mm	67 mm

## Electrical Ratings

Voltage - Maximum	600 V
-------------------	-------

## Conductor Related

Conductor - AL Str Size	10 AWG;9 AWG;8 AWG;7 AWG;6 AWG;5 AWG;4 AWG;3 AWG;2 AWG;1 AWG;1/0 ;2/0 AWG;3/0 AWG;4/0 AWG;250 kcmil
Conductor - AL Str Size Range	10 AWG - 250 kcmil
Conductor - Copper Str Size	10 AWG;9 AWG;8 AWG;7 AWG;6 AWG;5 AWG;4 AWG;3 AWG;2 AWG;1 AWG;1/0 ;2/0 AWG;3/0 AWG;4/0 AWG;250 kcmil
Conductor - Copper Str Size Range	10 AWG - 250 kcmil
Conductor Size	10 AWG-250 KCMIL
Conductor Type	<ul style="list-style-type: none"><li>AL C Str-Size</li><li>CU C Str-Size</li></ul>

## Certifications and Compliance

Certification - CSA Approved	Yes
Certification - UL Listed Direct Burial	No
Standards - RoHS Compliance Status	CM
UL Listed	Yes

## Logistics

Minimum Pack Quantity	1
-----------------------	---

## Product Assets

[Catalogs - UNITAP™ Products](#)  
[Customer Notices - Prop 65 Notice](#)  
[Sales Drawings - 50007090](#)



A proud member of the Hubbell Family.

©2024 Hubbell Incorporated. All rights reserved.  
BRDY-1PLMD25012-SPEC-EN | REV 1/2024