




1PLMD3506, UV Rated Black, Mount Tap, 2-sided, 6-port

By Burndy
Catalog # [1PLMD3506](#)

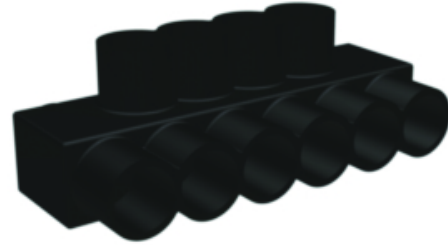

Mounted Block Tap Connector, 6 Ports, Single Side Entry, 7.92 IN L.

General

Connector Type	Multi Tap
Hex Key	1/3
Installation Torque Recommended in-lb	375 LBS/in
Insulation	Y
Insulation Type	Plastisol
Material	Aluminum
Number Of Ports	6
Physical Attribute - Number of Screws	8
Physical Attribute - Screw Type	Allen
Plated	N
Plating Type	Unplated
Temperature Rating	194
UPC	781810307656
UPC 12 Digit	7818103076566

Dimensions

Dimension - Height fraction	2.5 in
Dimension - Height inch	2.50 in
Dimension - L Length Overall mm	189 mm
Dimension - Length Overall inch	7.43 in
Dimension - Width inch	3.00 in
Dimension - Width mm	76 mm

Electrical Ratings

Voltage - Maximum	600 V
-------------------	-------

Conductor Related

Conductor - AL Str Size	8 AWG;6 AWG;4 AWG;3 AWG;2 AWG;1 AWG;1/0 AWG;2/0 AWG;3/0 AWG;4/0 AWG;250 kcmil;266 kcmil;300 kcmil;336 kcmil;350 kcmil
Conductor - AL Str Size Range	8 AWG-350 kcmil
Conductor - Copper Str Size	10 AWG;9 AWG;8 AWG;7 AWG;6 AWG;5 AWG;4 AWG;3 AWG;2 AWG;1 AWG;1/0 ;2/0 AWG;3/0 AWG;4/0 AWG;250 kcmil;300 kcmil;350 kcmil
Conductor - Copper Str Size Range	10 AWG - 350 kcmil
Conductor Size	10 AWG-350 KCMIL
Conductor Type	<ul style="list-style-type: none">AL C Str-SizeCU C Str-Size

Certifications and Compliance

Certification - CSA Approved	Yes
Certification - ETL	No
Certification - UL Listed Direct Burial	No
Certification - UL Recognized	No
Certification - cULus	No
Standards - RoHS Compliance Status	CM
UL Listed	Yes

Logistics

Minimum Pack Quantity	1
-----------------------	---

Product Assets

[Catalogs - UNITAP™ Products](#)
[Customer Notices - Prop 65 Notice](#)
[Sales Drawings - 50015723](#)



A proud member of the Hubbell Family.

©2024 Hubbell Incorporated. All rights reserved.
BRDY-1PLMD3506-SPEC-EN | REV 1/2024

