


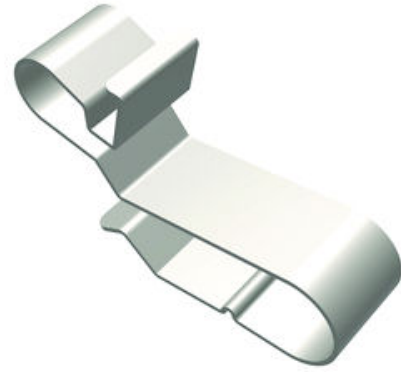

## ACC-R2, Rail Cable Clip, 1 wire Max 0.55"; 2 wire Max 0.43"

By Burndy  
Catalog # [ACC-R2](#)

Rail Cable Clips.



### Application

1 to 2 PV wires, Micro Inverter Trunk or AC cables  
Wire Diameter Range: 4.1mm - 8.0mm per each cable (2 cables) 4.1mm - 14.0mm per each cable (1 cable)

### General

Item Type	3B
Material	304 Stainless Steel
Mounting Method	Racking: Unirac, Ironrigde, Everest or similar rack profiles
Trade Name	WILEY
Type	Cable Clips
UPC	781810537084
UPC 12 Digit	7818105370844

### Dimensions

Dimension - Thread Size -

### Certifications And Compliance

Certification - CSA Approved	Yes
Certification - ETL	N
Certification - UL Recognized	N
Certification - cULus	Yes
Certified Listed	UL1565
Industry Standard(s)	UL1565
Standards - RoHS Compliance Status	CM
UL Listed	Yes

### Logistics

Carton Quantity	4000
-----------------	------

### Product Assets

[Catalogs - Wiley\\_WireManagementSolutions\\_Cat](#)  
[Catalogs - Full Line BURNDY Catalog](#)  
[Customer Notices - Prop 65 Notice](#)  
[Sales Drawings - 30023999](#)



A proud member of the Hubbell Family.

©2024 Hubbell Incorporated. All rights reserved.  
BRDY-ACC-R2-SPEC-EN | REV 5/2024