




# ACC-R4, Rail Cable Clip, Up to 4 0.29" PV wires

By Burndy  
Catalog # [ACC-R4](#)

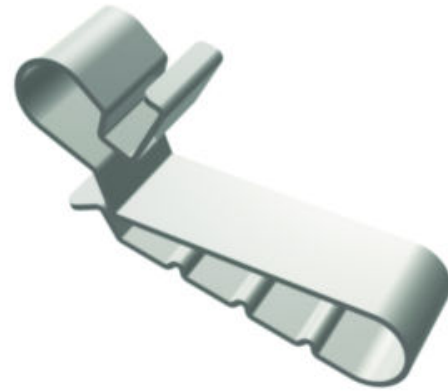

Rail Cable Clips.

## Features

304 Stainless Steel Clips that install on the rail, channel, or slot

## Application

1 to 4 PV wires, Wire Diameter Range: 4.1mm - 6.5mm per each cable

## General

Catalog Number	ACC-R4
Construction Material - Main	Nylon
EU RoHS Indicator	Contact Manufacturer
Item Type	3B
Material	304 Stainless Steel
Mounting Method	Racking: Unirac, Ironrigde, Everest or similar rack profiles
Sub Brand	Wiley
Trade Name	WILEY
Type	Cable Clips
UPC	781810537091
UPC 12 Digit	7818105370911

## Dimensions

Dimension - Thread Size -

## Certifications And Compliance

Certification - CSA Approved	Yes
Certification - ETL	N
Certification - UL Recognized	N
Certification - cULus	Yes
Certified Listed	UL1565
Industry Standard(s)	UL1565
Standards - RoHS Compliance Status	CM
UL Listed	Yes

## Logistics

Carton Quantity	4000
-----------------	------

## Product Assets

[Catalogs - Wiley\\_WireManagementSolutions\\_Cat](#)  
[Catalogs - Full Line BURNDY Catalog](#)  
[Catalogs - Section E4 - Wiley Grounding](#)  
[Catalogs - Section G - Wire Management](#)  
[Customer Notices - Prop 65 Notice](#)  
[Sales Drawings - 30023996](#)



A proud member of the Hubbell Family.

©2024 Hubbell Incorporated. All rights reserved.  
BRDY-ACCR4-SPEC-EN | REV 6/2024