


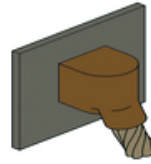

# B2478, Angular Cable Drop to Vertical Steel Pipe, 4 AWG, 6" to 10" Pipe

By Burndy  
Catalog # B2478

Mold, Angular Cable Drop to Vertical Steel Pipe, 4 AWG, 6" to 10" Pipe, 45 Weld Metal.



## Application

For Joining End Of A Copper Cable At A 45 DEG Angle To A Vertical Steel Surface

## General

EU RoHS Indicator	Yes
Sub Brand	BURNDYWELD
UPC	781810388600
UPC 12 Digit	7818103886000

## Conductor Related

Conductor - Copper Str Size	4 AWG
Conductor - Copper Str Size Range	4 AWG
Conductor - Rigid Pipe Size	6 in-10 in
Conductor - Rigid Pipe Size Range	6 in-10 in
Conductor Type	<ul style="list-style-type: none"><li>• CU C Str-Size</li><li>• Pipe Rigid-Size</li></ul>

## Certifications and Compliance

Standards - RoHS Compliance CM Status

## Logistics

Minimum Pack Quantity 1

## Product Assets

[Catalogs - Full Line BURNDY Catalog](#)  
[Sales Drawings - 10051631](#)



A proud member of the Hubbell Family.

©2024 Hubbell Incorporated. All rights reserved.  
BRDY-B2478-SPEC-EN | REV 1/2024