


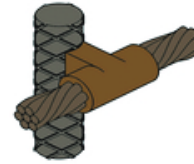

# B7640, Horizontal through Cable to Vertical Rebar, 1/0 AWG, #5 Rebar

By Burndy  
Catalog # [B7640](#)

Mold, Horizontal through Cable to Vertical Rebar, 1/0 AWG, #5 Rebar, 115 Weld Metal.



## Application

Recommended for horizontal conductors to vertical rebar connections for solid or concentric stranded conductors #6 through 4/0 joined to reinforcing bars #3 through #7 & larger

## General

EU RoHS Indicator	Yes
Sub Brand	EXOTHERMIC MOLDS
Trade Name	BURNDYWeld®
UPC	781810409329
UPC 12 Digit	7818104093299

## Conductor Related

Cable Size	1/0 AWG
Conductor - Copper Str Size	1/0
Conductor - Copper Str Size Range	1/0 AWG
Conductor - Rebar Size	#5
Conductor - Rebar Size Range	5
Conductor Type	<ul style="list-style-type: none"><li>• CU C Str-Size</li><li>• Rebar-Size</li></ul>

## Certifications and Compliance

Standards - RoHS Compliance CM Status

## Logistics

Minimum Pack Quantity 1

## Product Assets

[Catalogs - Full Line BURNDY Catalog](#)  
[Sales Drawings - 10051619](#)



A proud member of the Hubbell Family.

©2024 Hubbell Incorporated. All rights reserved.  
BRDY-B7640-SPEC-EN | REV 1/2024