



# BIBD2/04FXMT, Single Sided Mounted Flex Rated Four Conductor Clear Insulated Multi-Tap Connector

By Burndy  
Catalog # BIBD2/04FXMT

Aluminum UNITAP, Mountable Double Sided Entry, #14-2/0 Class B & C ,#14-#1 Class G,H,I,K, DLO, 4 PORT.

## Features


- Clear Plastisol covered AL6061-T6 aluminum body saves times and lowers installation costs and eliminates taping
- Clear plastisol allows visual confirmation that conductor is properly inserted
- Oxide inhibitor pre-installed inhibits moisture and contaminants from entering the contact area
- Range-taking capability reduces number of connectors necessary to carry in inventory
- Suitable for Code and Flex Conductor
- Color-coordinated conductor port caps display wire range and classes of conductor accepted
- Screw port caps show installation torque information for easy reference

## General

Catalog Number	BIBD2/04FXMT
Connector Type	Multi Tap
Material	Aluminum
UPC	621945439467

## Electrical Ratings

Voltage - Maximum	600 V
-------------------	-------

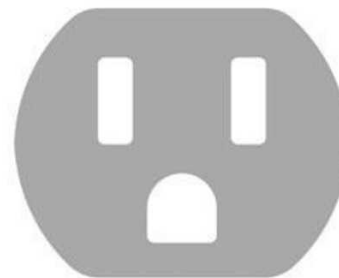

**Oh No!**  
IMAGE COMING SOON

## Conductor Related

Conductor Size	14-2/0 AWG
----------------	------------

## Certifications And Compliance

Certification - CSA Approved	Yes
Standards - RoHS Compliance	CM
Status	
UL Listed	Yes

## Logistics

Minimum Pack Quantity	5
-----------------------	---

## Product Assets

- [Catalogs - UNITAP™ Products](#)
- [Catalogs - BURNDY Master Catalog - Section A - Mechanical](#)
- [Catalogs - BURNDY Master Catalog - Full Line BURNDY Catalog](#)
- [Customer Notices - Prop 65 Notice](#)
- [Interactive Catalog - BURNDY Full-Line Digital Catalog](#)
- [Sales Drawings - 50050187](#)
- [Specifications - BURNDY\\_BIBD204FXMT\\_Specsheet](#)
- [Specifications - BIBD2/04FXMT](#)