


BIBD75010HD, Double Sided Heavy Duty Clear Insulated Ten Conductor Mult-Tap Connector

By Burndy
Catalog # [BIBD75010HD](#)

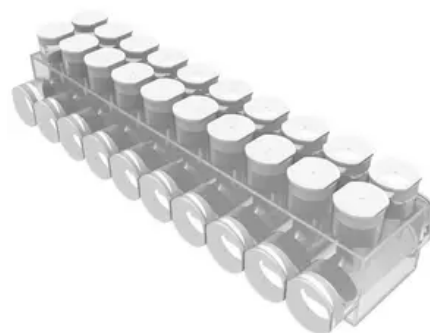

750-2 TWO-SIDED 10 PORT HD CLR.

Features

- PLASTISOL COVERED AL 6060-T6 BODY: SAVES TIME, LOWERS INSTALLATION COST, ELIMINATES TAPING
- OXIDE-IN HIBITOR IS PREFILLED: INHIBITS MOISTURE AND CONTAMINATES FROM ENTERING THE CONTACT AREA
- WIRE AND SCREW PORT COVERS: PROTECTS AGAINST CONTAMINATION AND ACCIDENTAL CONTACT OF ENERGIZED PARTS

Application

For Indoor Use Only, Copper Or Stranded Aluminum

General

Catalog Number	BIBD75010HD
Connector Type	Multi Tap
Hex Key	3/8 in
Material	Aluminum
Material - Body	Tin Plated Aluminum
Material - Insulation	Plastisol
Material Type - Screw	Clear Coated Aluminum
Number Of Ports	10
Operating Temperature	-40°C TO 135°C.
UPC	621945480889

Dimensions

Length	13.63 in
Width	4.83 in

Electrical Ratings

Amperage Rating	535 A
Voltage - Maximum	600 V
Voltage Rating	600 V

Conductor Related

Conductor Size	2 AWG-750 KCMIL
Wire Size	#2 AWG TO 750 kcmil Class B, C

Certifications And Compliance

Certification - CSA Approved	Yes
Certification - ETL	No
Standards - RoHS Compliance	CM
Status	
UL Listed	Yes

Logistics

Minimum Pack Quantity	1
-----------------------	---

Product Assets

[Catalogs - BURNDY Master Catalog - Full Line BURNDY Catalog](#)
[Customer Notices - Prop 65 Notice](#)
[Interactive Catalog - BURNDY Full-Line Digital Catalog](#)
[Sales Drawings - 50079817](#)
[Specifications - BIBD75010HD](#)