




# BIBD75012HD, Double Sided Heavy Duty Clear Insulated Twelve Conductor Mult-Tap Connector

By Burndy  
Catalog # [BIBD75012HD](#)

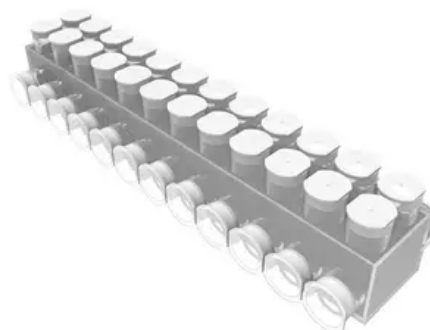

750-2 TWO-SIDED 12 PORT HD CLR.

## Application

For Indoor Use Only, Copper Or Stranded Aluminum

## General

Catalog Number	BIBD75012HD
Connector Type	Multi Tap
Hex Key	3/8 in
Material	Aluminum
Material - Body	Tin Plated Aluminum
Material - Insulation	Plastisol
Material Type - Screw	Clear Coated Aluminum
Number Of Ports	12
Operating Temperature	-40°C TO 135°C.
UPC	621945480896

## Dimensions

Length	16.38 in
Width	4.83 in

## Electrical Ratings

Amperage Rating	535 A
Voltage - Maximum	600 V

Voltage Rating	600 V
----------------	-------

## Conductor Related

Conductor Size	2 AWG-750 KCMIL
Wire Size	#2 AWG TO 750 kcmil Class B, C

## Certifications And Compliance

Certification - CSA Approved	Yes
Certification - ETL	No
Standards - RoHS Compliance	CM
Status	
UL Listed	Yes

## Logistics

Minimum Pack Quantity	1
-----------------------	---

## Product Assets

- [Catalogs - BURNDY Master Catalog - Full Line BURNDY Catalog](#)
- [Customer Notices - Prop 65 Notice](#)
- [Interactive Catalog - BURNDY Full-Line Digital Catalog](#)
- [Sales Drawings - 50079817](#)
- [Specifications - BIBD75012HD](#)