




BIBD7503HD, Double Sided Heavy Duty Clear Insulated Three Conductor Mult-Tap Connector

By Burndy
Catalog # BIBD7503HD

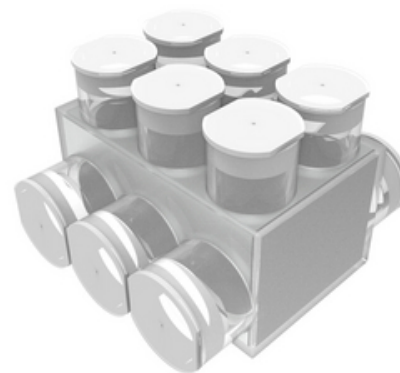

750-2 TWO-SIDED 3 PORT HD CLR.

Application

For Indoor Use Only, Copper Or Stranded Aluminum

General

| | |
|-----------------------|-----------------------|
| Catalog Number | BIBD7503HD |
| Connector Type | Multi Tap |
| Hex Key | 3/8 in |
| Material | Aluminum |
| Material - Body | Tin Plated Aluminum |
| Material - Insulation | Plastisol |
| Material Type - Screw | Clear Coated Aluminum |
| Number Of Ports | 3 |
| Operating Temperature | -40°C TO 135°C. |
| UPC | 621945480834 |

Dimensions

| | |
|--------|---------|
| Length | 4 in |
| Width | 4.83 in |

Electrical Ratings

| | |
|-------------------|-------|
| Amperage Rating | 535 A |
| Voltage - Maximum | 600 V |
| Voltage Rating | 600 V |

Conductor Related

| | |
|----------------|--------------------------------|
| Conductor Size | 2 AWG-750 KCMIL |
| Wire Size | #2 AWG TO 750 kcmil Class B, C |

Certifications And Compliance

| | |
|------------------------------------|-----|
| Certification - CSA Approved | Yes |
| Certification - ETL | No |
| Standards - RoHS Compliance Status | CM |
| UL Listed | Yes |

Logistics

| | |
|-----------------------|---|
| Minimum Pack Quantity | 1 |
|-----------------------|---|

Product Assets

- [Catalogs - BURNDY Master Catalog - Full Line BURNDY Catalog](#)
- [Customer Notices - Prop 65 Notice](#)
- [Interactive Catalog - BURNDY Full-Line Digital Catalog](#)
- [Sales Drawings - 50079817](#)
- [Specifications - BIBD7503HD](#)