




BIBD7504HD, Double Sided Heavy Duty Clear Insulated Four Conductor Mult-Tap Connector

By Burndy
Catalog # [BIBD7504HD](#)

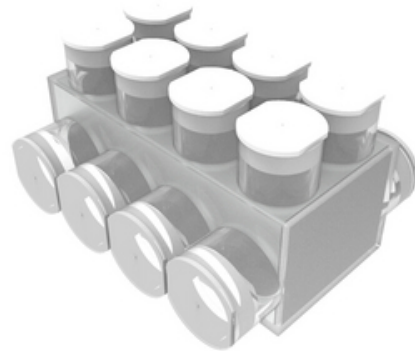

750-2 TWO-SIDED 4 PORT HD CLR.

Application

For Indoor Use Only, Copper Or Stranded Aluminum

General

| | |
|-----------------------|-----------------------|
| Connector Type | Multi Tap |
| Hex Key | 3/8 in |
| Material | Aluminum |
| Material - Body | Tin Plated Aluminum |
| Material - Insulation | Plastisol |
| Material Type - Screw | Clear Coated Aluminum |
| Number Of Ports | 4 |
| Operating Temperature | -40°C TO 135°C. |
| UPC | 621945480841 |

Dimensions

| | |
|--------|---------|
| Length | 5.38 in |
| Width | 4.83 in |

Electrical Ratings

| | |
|-------------------|-------|
| Amperage Rating | 535 A |
| Voltage - Maximum | 600 V |
| Voltage Rating | 600 V |

Conductor Related

| | |
|----------------|--------------------------------|
| Conductor Size | 2 AWG-750 KCMIL |
| Wire Size | #2 AWG TO 750 kcmil Class B, C |

Certifications And Compliance

| | |
|------------------------------------|-----|
| Certification - CSA Approved | Yes |
| Certification - ETL | No |
| Standards - RoHS Compliance Status | CM |
| UL Listed | Yes |

Logistics

| | |
|-----------------------|---|
| Minimum Pack Quantity | 1 |
|-----------------------|---|

Product Assets

[Catalogs - Full Line BURNDY Catalog](#)
[Customer Notices - Prop 65 Notice](#)
[Sales Drawings - 50079817](#)



A proud member of the Hubbell Family.

©2024 Hubbell Incorporated. All rights reserved.
BRDY-BIBD7504HD-SPEC-EN | REV 5/2024