

C11JPT, Cast Bronze Clamp, Cable to Water Pipe

By Burndy
Catalog # [C11JPT](#)

Cast Bronze Clamp, Cable to Water Pipe, 10 AWG - 6 AWG, 1/2" - 1" Water Pipe, 1/2" Hub.

Features

- Pressure bar type conduit hub adjusts for 1/2", 3/4" EMT, or 1/2" rigid conduit
- Supplied with zinc plated hardware

General


Catalog Number	C11JPT
Material	Bronze Alloy
Material - Hardware Plated	Zinc Plated Steel N
Plating Type	Unplated
UPC	781810142257
UPC 14 Digit GTIN	00781810142257

Dimensions

Dimension - Height inch	2.07 in
Dimension - Height mm	52.6 mm
Dimension - L Length Overall mm	81 mm
Dimension - Length Overall inch	3.19 in
Dimension - Width inch	2.13 in
Dimension - Width mm	54 mm

Conductor Related

Conductor - Armored Cable Size	N
Conductor - Copper Solid Size	10 AWG;9 AWG;8 AWG;7 AWG;6 AWG
Conductor - Copper Solid Size Range	10 AWG-6 AWG
Conductor - Copper Str Size	8 AWG;7 AWG;6 AWG

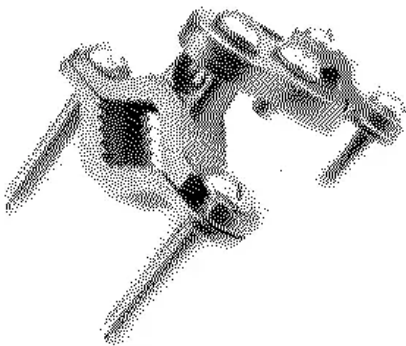

Conductor - Copper Str Size Range	8 AWG - 6 AWG
Conductor - Pipe EMT Size	1/2 in;3/4 in;1 in
Conductor - Pipe EMT Size Range	1/2 in-1 in
Conductor Type	<ul style="list-style-type: none">• Pipe EMT-Size• CU C Solid-Size

Certifications And Compliance

Buy America(n) Qualified	Contact Manufacturer
Certification - CSA Approved	No
Certification - ETL	No
Certification - UL Listed Direct Burial	No
Certification - UL Recognized	No
Certification - cULus	No
Industry Standard(s)	UL467
Standards - Industry Standards Met	UL467
Standards - RoHS Compliance	NC
Status	
UL Listed	Yes

Logistics

Minimum Pack Quantity	30
-----------------------	----

Product Assets

[Catalogs - Burndy Grounding Catalog](#)
[Catalogs - BURNDY Master Catalog - Full Line BURNDY Catalog](#)
[Customer Notices - Prop 65 Notice](#)
[Interactive Catalog - BURNDY Full-Line Digital Catalog](#)
[Product Cross Section Image\(s\) - BUR_CJPT_LineArt](#)
[Sales Drawings - sc210672-01](#)
[Specifications - C11JPT](#)