


C11LH1, Cast Bronze Clamp, Cable to Water Pipe

By Burndy
Catalog # [C11LH1](#)

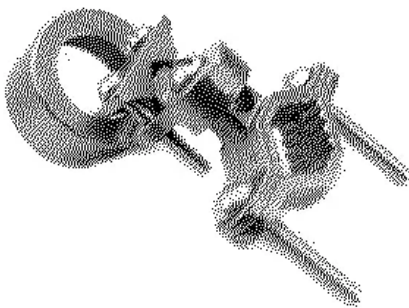

Cast Bronze Clamp, Cable to Water Pipe, 10 AWG -6 AWG, 1/2" - 1" Water Pipe, 1/2" hub.

Features

- Cast bronze clamps for conduit
- Continuity from rigid conduit systems to ground provided by cast bronze threaded conduit hub
- Zinc plated screws

Application

For Grounding Rigid Conduit Systems

General

Catalog Number	C11LH1
EU RoHS Indicator	No
Material	Bronze Alloy
Material - Hardware	Zinc Plated Steel
Plated	N
Plating Type	Unplated
Sub Brand	CONDUIT
Type	WaterPipe Grounding Connectors
UPC	781810142141
UPC 14 Digit GTIN	00781810142141

Dimensions

Dimension - Height inch	2.25 in
Dimension - Height mm	57.2 mm
Dimension - L Length Overall mm	82 mm
Dimension - Length Overall inch	3.23 in
Dimension - Pad Width inch	0.97 in
Dimension - Width inch	0.69 in
Dimension - Width mm	18 mm

Conductor Related

Conductor - Armored Cable Size	N
Conductor - Copper Solid Size	10 AWG

Conductor - Copper Solid Size Range	10 AWG
Conductor - Copper Str Size	10 AWG;9 AWG;8 AWG;7 AWG;6 AWG
Conductor - Copper Str Size Range	10 AWG - 6 AWG
Conductor - Pipe EMT Size	1/2 in;3/4 in;1 in
Conductor - Pipe EMT Size Range	1/2 in-1 in

Certifications And Compliance

Buy America(n) Qualified	Contact Manufacturer
Certification - CSA Approved	No
Certification - ETL	No
Certification - UL Listed Direct Burial	No
Certification - UL Recognized	No
Certification - cULus	No
Industry Standard(s)	UL467
Standards - Industry Standards Met	UL467
Standards - RoHS Compliance Status	NC
UL Listed	Yes

Logistics

Minimum Pack Quantity	1
-----------------------	---

Product Assets

[3D Models - C11LH1_MODEL-PDF](#)
[3D Models - C11LH1_MODEL-STEP](#)
[3D Models - C11LH1_MODEL-IGES](#)
[Catalogs - Burndy Grounding Catalog](#)
[Catalogs - BURNDY Master Catalog - Full Line BURNDY Catalog](#)
[Customer Notices - Prop 65 Notice](#)
[Interactive Catalog - BURNDY Full-Line Digital Catalog](#)
[Sales Drawings - sc210670-01](#)
[Specifications - C11LH1](#)