


# C4LH3, Cast Bronze Clamp, Cable to Water Pipe

By Burndy  
Catalog # [C4LH3](#)

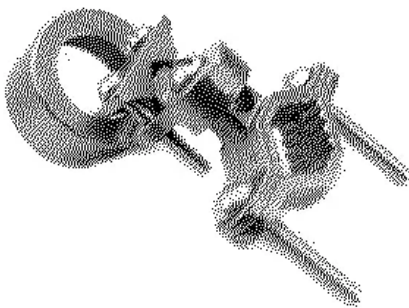

Cast Bronze Clamp,Cable to Water Pipe, 3/0 AWG - 10 AWG, 2-1/2" - 4" Water Pipe, 1" hub.

## Features

- Cast bronze clamp for grounding rigid conduit systems
- Continuity from rigid conduit systems to ground provided by cast bronze threaded conduit hub
- Supplied with zinc plated screws
- UL467 Listed for the US and Canadian markets

## General

Catalog Number	C4LH3
Material	Bronze Alloy
Material - Hardware Plated	Zinc Plated Steel
Plating Type	N
UPC	781810142233
UPC 14 Digit GTIN	00781810142233

## Dimensions

Dimension - Height inch	5.01 in
Dimension - Height mm	127.3 mm
Dimension - L Length Overall mm	122 mm
Dimension - Length Overall inch	4.82 in
Dimension - Pad Width inch	2.44 in
Dimension - Width inch	1.13 in
Dimension - Width mm	29 mm

## Conductor Related

Conductor - Armored Cable Size	N
Conductor - Copper Str Size	10 AWG;9 AWG;8 AWG;7 AWG;6 AWG;5 AWG;4 AWG;3 AWG;2 AWG;1 AWG;1/0 AWG;2/0 AWG;3/0 AWG

Conductor - Copper Str Size Range	10 AWG - 3/0 AWG
Conductor - Pipe EMT Size	2 1/2 in;3 in;3 1/2 in;4 in
Conductor - Pipe EMT Size Range	2 1/2 in-4 in

## Certifications And Compliance

Buy America(n) Qualified	Contact Manufacturer
Certification - CSA Approved	No
Certification - ETL	No
Certification - UL Listed Direct Burial	No
Certification - UL Recognized	No
Certification - cULus	No
Industry Standard(s)	UL467
Standards - Industry Standards Met	UL467
Standards - RoHS Compliance	NC
Status	
UL Listed	Yes

## Logistics

Minimum Pack Quantity	1
-----------------------	---

## Product Assets

- [3D Models - C4LH3\\_MODEL-STEP](#)
- [3D Models - C4LH3\\_MODEL-IGES](#)
- [3D Models - C4LH3\\_MODEL-PDF](#)
- [Catalogs - Burndy Grounding Catalog](#)
- [Catalogs - BURNDY Master Catalog - Full Line BURNDY Catalog](#)
- [Customer Notices - Prop 65 Notice](#)
- [Interactive Catalog - BURNDY Full-Line Digital Catalog](#)
- [Sales Drawings - sc210670-01](#)
- [Specifications - C4LH3](#)