




# CS3CO2528140B, Medium Voltage Cold Shrink Termination Kit, 25-28kV 3-Phase Conversion Series- Outdoor, Sleeve with Boot for Bare Concentric Conductor

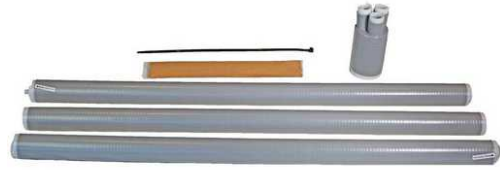

By Burndy  
Catalog # CS3CO2528140B

The Type CS3CO2528-B Series of 3 Phase Conversion Kits with Outdoor Sleeves with Boot for Bare Concentric Conductor. Conversion kits includes outdoor cold shrinkable tube (unprinted), 3-leg boot, seal, cable tie, and installation guide. Conforms to IEEE-48-2009, Class 1 and ISO/IEC 17025 Standards. Test reports available upon request.

## Features

- Rip and Grip! Does not require heat gun or any installation tools
- Spiral rip cord design provides for easy installation with effortless unwinding providing for fast removal of the hold-out core, Rip cord is recyclable
- All kits supplied with outdoor cold shrinkable tube (unprinted), 3-leg boot, seal, cable tie, and installation guide
- Quick, easy, cost effective installation utilizing one-piece terminator design
- Test reports available upon request

## Application

To be used with Single Conductor, 25-28 kV XPLE and EPR non-shielded power cables for the Electrical/Industrial/Construction market.

## General

Boot Type	YES
Environmental Conditions	Outdoor
Material	Caoutchouc de silicone
Series	UD-BC
Type	<ul style="list-style-type: none"><li>• CS3CO2528-B</li><li>• CS3CO2528-B</li></ul>
UPC	621945584952

## Electrical Ratings

Phase	3-Phase
Voltage Rating	25/28 kV

## Conductor Related

Conductor Range	<ul style="list-style-type: none"><li>• 5-8kV: 2/0 AWG-500 kcmil</li><li>• 15kV: 2/0 AWG-250 kcmil</li><li>• 25-28kV: #1-2/0 AWG</li></ul>
-----------------	--

## Logistics

Carton Quantity	1
-----------------	---

## Product Assets

[Brochures - Cold Shrink Medium Voltage Cable Terminations Brochure](#)  
[Catalog Page - BURNDY\\_MVColdShrinkTerminationKits\\_CS3CO-B\\_CatCut](#)  
[Catalogs - BURNDY Master Catalog - Section D - Shrink Tubing](#)  
[Sales Drawings - 50095782](#)



A proud member of the Hubbell Family.

©2024 Hubbell Incorporated. All rights reserved.  
BRDY-CS3CO2528140B-SPEC-EN | REV 1/2024