




CT120200L, Cable Tie, 120 Lb Tensile, Natural

By Burndy
Catalog # [CT120200L](#)

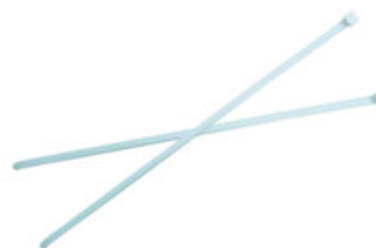

Nylon UNIRAP - 120 Lb. Tensile Strength.

Features

Standard Cable Tie

General

Catalog Number	CT120200L
Color	Natural
Installation Torque	12 LBS/in
Recommended in-lb	
Material	NYLON 6/6
Operating Temperature Celcius Max	85 °C
Operating Temperature Celcius Min	-40 °C
Rating - Minimum Tensile Strength lbs	120
Tool Type	Standard
Trade Name	UNIRAP™
UPC	781810332924

Dimensions

Dimension - Bundle Diameter Max inch	2
Dimension - L Length Overall mm	221 mm
Dimension - Length Overall inch	8.70 in
Dimension - Width inch	0.30 in
Dimension - Width mm	8 mm

Certifications And Compliance

Certification - 94V0 Rated	N
Certification - CSA Approved	No
Certification - ETL	No
Certification - UL Recognized	No
Certification - UV Rated	No
Certification - cULus	No
Standards - RoHS Compliance Status	CM
UL Listed	Yes

Logistics

Carton Quantity	2500
Minimum Pack Quantity	1000
Packaging Type	Bag

Product Assets

- [Catalogs - BURNDY Master Catalog - Full Line BURNDY Catalog](#)
- [Interactive Catalog - BURNDY Full-Line Digital Catalog](#)
- [Product Cross Section Image\(s\) - BUR_CT_UNIRAP_CABLE_TIE_LineArt](#)
- [Sales Drawings - 50080813](#)
- [Specifications - CT120200L](#)