




CT120200L2, Cable Tie, 120 Lb Tensile

By Burndy
Catalog # [CT120200L2](#)

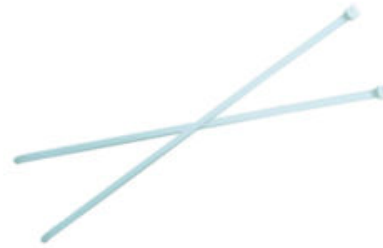

Nylon UNIRAP - 120 Lb. Tensile Strength.

Features

Standard Cable Tie

General

Color	Red
Material	NYLON 6/6
Rating - Minimum Tensile Strength N	120
Trade Name	UNIRAP™
UPC	781810332948
UPC 12 Digit	7818103329488

Dimensions

Dimension - Bundle Diameter Max inch	2
Dimension - L Length Overall mm	225 mm
Dimension - Length Overall inch	8.87 in
Dimension - Width fraction	3/10 in
Dimension - Width inch	0.3 in
Dimension - Width mm	8 mm

Certifications And Compliance

Certification - 94V0 Rated	No
Certification - CSA Approved	No
Certification - ETL	No
Certification - UL Recognized	No
Certification - UV Rated	No
Certification - cULus	No
Standards - RoHS Compliance Status	UI
UL Listed	No

Logistics

Carton Quantity	1000
Minimum Pack Quantity	20000

Product Assets

[Catalogs - Full Line BURNDY Catalog](#)
[Product Cross Section Image\(s\) - BUR_CT_UNIRAP_CABLE_TIE_LineArt](#)
[Sales Drawings - 50004623](#)



A proud member of the Hubbell Family.