




CT120300L, Cable Tie, 3" Max Bundle, 120 Lb Tensile, Natural

By Burndy
Catalog # [CT120300L](#)

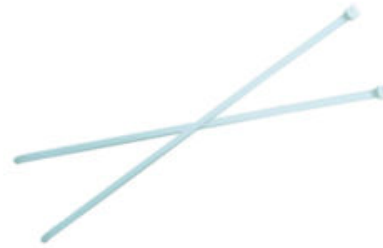

Nylon UNIRAP - 120 Lb. Tensile Strength.

Features

Standard Cable Tie

General

Color	Natural
Material	NYLON 6/6
Operating Temperature Celcius Max	85 °C
Operating Temperature Celcius Min	-40 °C
Rating - Minimum Tensile Strength lbs	120
Tool Type	Standard
UPC	781810333044

Dimensions

Dimension - Bundle Diameter Max inch	3
Dimension - L Length Overall mm	305 mm
Dimension - Length Overall inch	12 in
Dimension - Width inch	0.30 in
Dimension - Width mm	8 mm

Certifications And Compliance

Certification - 94V0 Rated	N
Certification - CSA Approved	No
Certification - ETL	No
Certification - UL Recognized	No
Certification - UV Rated	No
Certification - cULus	No
Standards - RoHS Compliance Status	CM
UL Listed	No

Logistics

Carton Quantity	2000
Minimum Pack Quantity	50
Packaging Type	Bag

Product Assets

[Catalogs - Full Line BURNDY Catalog](#)
[Product Cross Section Image\(s\) - BUR_CT_UNIRAP_CABLE_TIE_LineArt](#)
[Sales Drawings - 50080813](#)



A proud member of the Hubbell Family.

©2024 Hubbell Incorporated. All rights reserved.
BRDY-CT120300L-SPEC-EN | REV 5/2024