


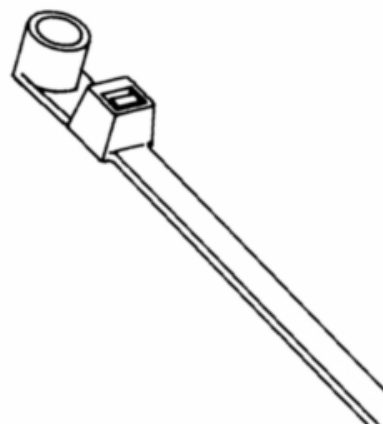

CT120400MH14L, Cable Tie, 120 Lb Tensile, Natural, Screw Mount

By Burndy
Catalog # [CT120400MH14L](#)

Nylon Natural Screw Mounting Cable Tie.



Features

Mounting Hole

Application

For Screw Mount

General

Catalog Number	CT120400MH14L
Color	Natural
EU RoHS Indicator	Yes
Material	NYLON 6/6
Mounting Method	Screw
Operating Temperature Celcius Max	85 °C
Operating Temperature Celcius Min	-40 °C
Rating - Minimum Tensile Strength lbs	120
Sub Brand	UNIRAP,CABLE TIE
Trade Name	UNIRAP™
Type	Standard
UPC	781810335321

Dimensions

Dimension - Bundle Diameter Max inch	4
Dimension - L Length Overall mm	399 mm
Dimension - Length Overall inch	15.70 in
Dimension - Screw Size inch	1/4
Dimension - Width inch	0.30 in
Dimension - Width mm	8 mm

Certifications And Compliance

Buy American Compliant	Yes
Certification - 94V0 Rated	N
Certification - CSA Approved	No
Certification - ETL	No
Certification - UL Recognized	No
Certification - UV Rated	No
Certification - cULus	No
Standards - RoHS Compliance Status	CM
UL Listed	No

Logistics

Carton Quantity	1000
Minimum Pack Quantity	50

Product Assets

- [Catalogs - BURNDY Master Catalog - Full Line BURNDY Catalog](#)
- [Catalogs - BURNDY Master Catalog - Section G - Wire Management](#)
- [Interactive Catalog - BURNDY Full-Line Digital Catalog](#)
- [Product Cross Section Image\(s\) - BUR_CT_MH_UNIRAP_CABLE_TIE_LineArt](#)
- [Sales Drawings - 50080813](#)
- [Specifications - CT120400MH14L](#)