




CT1751100Q, Cable Tie, 11" Max Bundle, 175 Lb Tensile, Natural

By Burndy
Catalog # [CT1751100Q](#)

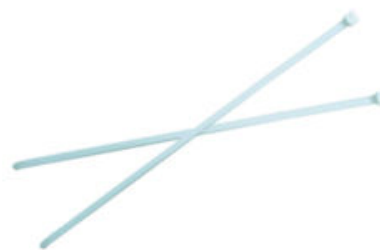

Nylon cable ties, Tensile strength-175 Lbs, Color- Natural, 36.50"L, 0.34"W, 11.00" Bundle Dia.

Features

Standard Cable Tie

General

Catalog Number	CT1751100Q
Color	Natural
Material	NYLON 6/6
Operating Temperature Celcius Max	85 °C
Operating Temperature Celcius Min	0 °C
Rating - Minimum Tensile Strength lbs	175
Tool Type	Heavy
Trade Name	UNIRAP™
UPC	781810333853

Dimensions

Dimension - Bundle Diameter Max inch	11
Dimension - L Length Overall mm	927 mm
Dimension - Length Overall inch	36.50 in
Dimension - Width inch	0.34 in
Dimension - Width mm	8.6 mm

Certifications And Compliance

Certification - 94V0 Rated	N
Certification - CSA Approved	No
Certification - ETL	No
Certification - UL Recognized	Yes
Certification - UV Rated	No
Certification - cULus	No
Military Spec Number	MS3367-13-9
Standards - RoHS Compliance Status	CM
UL Listed	No

Logistics

Carton Quantity	500
Minimum Pack Quantity	25
Packaging Type	Bag

Product Assets

- [Catalogs - BURNDY Master Catalog - Full Line BURNDY Catalog](#)
- [Catalogs - BURNDY Master Catalog - Section G - Wire Management](#)
- [Interactive Catalog - BURNDY Full-Line Digital Catalog](#)
- [Product Cross Section Image\(s\) - BUR_CT_UNIRAP_CABLE_TIE_LineArt](#)
- [Sales Drawings - 50080813](#)
- [Specifications - CT1751100Q](#)