




# CT1751100QUG, Cable Tie, 11" Max Bundle, 175 Lb Tensile, UV Black, Universal Grade

By Burndy  
Catalog # [CT1751100QUG](#)

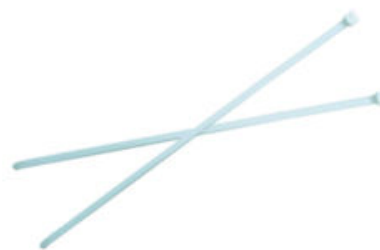

Nylon cable ties, Tensile strength-175 Lbs, Color- UV Black, 36.00"L, 0.35"W, 11.00" Bundle Dia.

## Features

Standard Cable Tie

## General

Catalog Number	CT1751100QUG
Color	Natural
Material	NYLON 6/6
Rating - Minimum Tensile Strength lbs	175
Tool Type	Heavy
Trade Name	UNIRAP™
UPC	781810486061

## Dimensions

Dimension - Bundle Diameter Max inch	11
Dimension - L Length Overall mm	914 mm
Dimension - Length Overall inch	36.00 in
Dimension - Width inch	0.35 in
Dimension - Width mm	8.9 mm

## Certifications And Compliance

Certification - CSA Approved	No
Certification - ETL	No
Certification - UL Recognized	Yes
Certification - UV Rated	No
Certification - cULus	No
Standards - RoHS Compliance	CM
Status	
UL Listed	No

## Logistics

Carton Quantity	500
Minimum Pack Quantity	25

## Product Assets

- [Catalogs - BURNDY Master Catalog - Full Line BURNDY Catalog](#)
- [Catalogs - BURNDY Master Catalog - Section G - Wire Management](#)
- [Interactive Catalog - BURNDY Full-Line Digital Catalog](#)
- [Product Cross Section Image\(s\) - BUR\\_CT\\_UNIRAP\\_CABLE\\_TIE\\_LineArt](#)
- [Sales Drawings - 30001461](#)
- [Specifications - CT1751100QUG](#)