




CT18075C, Cable Tie, .75" Max Bundle, 18 Lb Tensile, Natural

By Burndy
Catalog # [CT18075C](#)

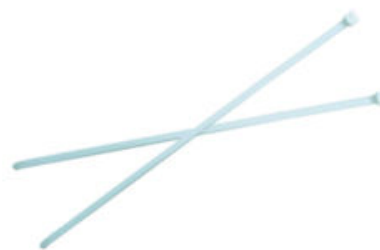

Natural Nylon 6/6 Cable Tie, 0.75" Max. Bundle Dia, 18 Lbs, 4" Long, 0.10" Wide, Install with TWT1, MK7, CTT50.

Features

Standard Cable Tie

Application

For General Purpose

General

Catalog Number	CT18075C
Color	Natural
EU RoHS Indicator	Yes
Material	NYLON 6/6
Military Specification	MS3367
Operating Temperature Celcius Max	85 °C
Operating Temperature Celcius Min	-40 °C
Rating - Minimum Tensile Strength lbs	18
Sub Brand	UNIRAP,CABLE TIE
Tool Type	Mini
Trade Name	UNIRAP™
Type	Mini
UPC	781810331323

Dimensions

Dimension - Bundle Diameter Max inch	0.75
Dimension - L Length Overall mm	104 mm
Dimension - Length Overall inch	4.10 in
Dimension - Width inch	0.10 in
Dimension - Width mm	2.5 mm

Certifications And Compliance

Buy American Compliant	Yes
Certification - 94V0 Rated	N
Certification - CSA Approved	No
Certification - ETL	No
Certification - UL Recognized	No
Certification - UV Rated	No
Certification - cULus	No
Industry Standard(s)	Military Specified (Mil-Spec)
Military Spec Number	MS3367-4-9
Standards - Industry Standards Met	Military Specified (Mil-Spec)
Standards - RoHS Compliance Status	CM
UL Listed	Yes

Logistics

Carton Quantity	1000
Minimum Pack Quantity	100

Product Assets

- [3D Models - CT18075C_MODEL-PDF](#)
- [3D Models - CT18075C_MODEL-IGES](#)
- [3D Models - CT18075C_MODEL-STEP](#)
- [Catalogs - BURNDY Master Catalog - Full Line BURNDY Catalog](#)
- [Catalogs - BURNDY Master Catalog - Section G - Wire Management](#)
- [Interactive Catalog - BURNDY Full-Line Digital Catalog](#)
- [Product Cross Section Image\(s\) - BUR_CT_UNIRAP_CABLE_TIE_LineArt](#)
- [Sales Drawings - 50080813](#)
- [Specifications - CT18075C](#)