


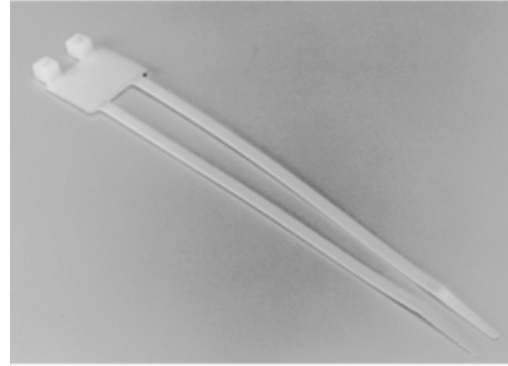

CT18075FLC, Cable Tie, .75" Max Bundle, 18 Lb Tensile, Natural, Identification

By Burndy
Catalog # [CT18075FLC](#)

Nylon cable ties, Tensile strength-18 Lbs, Color- Natural, 04.10"L, 0.10"W, 0.75" Bundle Dia.



Features

- Identification

General

Color	Natural
Material	NYLON 6/6
Rating - Minimum Tensile Strength lbs	18 lb
Trade Name	UNIRAP™
UPC	781810335376

Dimensions

Dimension - Bundle Diameter Max inch	0.75
Dimension - L Length Overall mm	104 mm
Dimension - Length Overall inch	4.10 in
Dimension - Marking Pad Size inch	0.36 X 0.81
Dimension - Width inch	0.10 in
Dimension - Width mm	2.5 mm

Certifications and Compliance

Certification - 94V0 Rated	N
Certification - CSA Approved	No
Certification - UV Rated	No
Standards - RoHS Compliance Status	CM

Logistics

Carton Quantity	20000
Minimum Pack Quantity	1000

Product Assets

[Catalogs - Full Line BURNDY Catalog](#)
[Sales Drawings - 50004698](#)



A proud member of the Hubbell Family.

©2024 Hubbell Incorporated. All rights reserved.
BRDY-CT18075FLC-SPEC-EN | REV 1/2024