


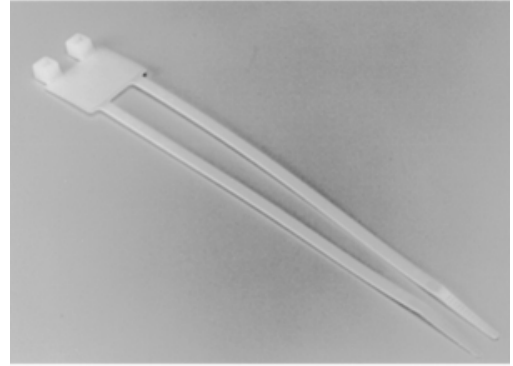

CT18075IDC, Cable Tie, .75" Max Bundle, 18 Lb Tensile, Natural, Identification

By Burndy
Catalog # [CT18075IDC](#)

Nylon cable ties, Tensile strength-18 Lbs, Color- Natural, 04.01"L, 0.10"W, 0.75" Bundle Dia.



Features

Identification

General

Color	Natural
Material	NYLON 6/6
Military Specification	MS3368
Operating Temperature Celcius Max	85 °C
Operating Temperature Celcius Min	-40 °C
Rating - Minimum Tensile Strength lbs	18
Trade Name	UNIRAP™
UPC	781810335369

Dimensions

Dimension - Bundle Diameter Max inch	0.75
Dimension - L Length Overall mm	104 mm
Dimension - Length Overall inch	4.10 in
Dimension - Marking Pad Size inch	0.33 X 1.00
Dimension - Width inch	0.10 in
Dimension - Width mm	2.5 mm

Certifications And Compliance

Certification - 94V0 Rated	N
Certification - CSA Approved	No
Certification - UV Rated	No
Industry Standard(s)	Military Specified (Mil-Spec)
Military Spec Number	MS3368-5-E
Standards - Industry Standards Met	Military Specified (Mil-Spec)
Standards - RoHS Compliance Status	CM

Logistics

Carton Quantity	1000
Minimum Pack Quantity	100
Packaging Type	Bag

Product Assets

[Catalogs - Full Line BURNDY Catalog](#)
[Product Cross Section Image\(s\) - BUR_CT_ID_UNIRAP_CABLE_TIE_LineArt](#)
[Sales Drawings - 50080813](#)



A proud member of the Hubbell Family.

©2024 Hubbell Incorporated. All rights reserved.
BRDY-CT18075IDC-SPEC-EN | REV 5/2024