




CT18200MUG, Cable Tie, 2" Max Bundle, 18 Lb Tensile, Natural, Universal Grade

By Burndy
Catalog # [CT18200MUG](#)

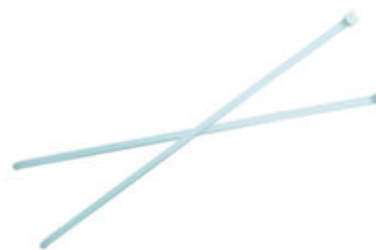

Nylon cable ties, Tensile strength-18 Lbs, Color- Natural, 7.95"L, 0.10"W, 2.00" Bundle Dia.

Features

Standard Cable Tie

General

Catalog Number	CT18200MUG
Color	Natural
Material	NYLON 6/6
Rating - Minimum Tensile Strength lbs	18
Tool Type	Mini
Trade Name	UNIRAP™
UPC	781810469033

Dimensions

Dimension - Bundle Diameter Max inch	2
Dimension - L Length Overall mm	202 mm
Dimension - Length Overall inch	7.95 in
Dimension - Width inch	0.10 in
Dimension - Width mm	2.5 mm

Certifications And Compliance

Certification - CSA Approved	No
Certification - ETL	No
Certification - UL Recognized	Yes
Certification - UV Rated	No
Certification - cULus	No
Standards - RoHS Compliance	CM
Status	
UL Listed	No

Logistics

Carton Quantity	40000
Minimum Pack Quantity	1000

Product Assets

- [Catalogs - BURNDY Master Catalog - Full Line BURNDY Catalog](#)
- [Catalogs - BURNDY Master Catalog - Section G - Wire Management](#)
- [Interactive Catalog - BURNDY Full-Line Digital Catalog](#)
- [Sales Drawings - 10092186](#)
- [Specifications - CT18200MUG](#)



A Hubbell brand