




CT250600RQ0, Cable Tie, 250 Lb Tensile, UV Black, Releasable

By Burndy
Catalog # [CT250600RQ0](#)

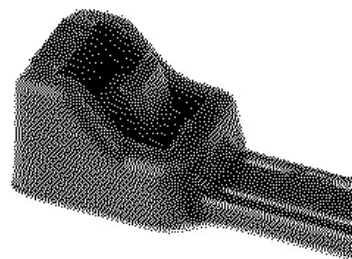

Nylon 6/6 Standard Releasable Cable Tie, UV Black, 250 Lbs Min Ten Strgth, 23.00" L, 0.50" W.

Features

Releaseable

Application

For Use Where Service Requires Adding Or Subtracting Wires From An Existing Wire Bundle

General

| | |
|---------------------------------------|-----------------------|
| Catalog Number | CT250600RQ0 |
| Color | Black |
| EU RoHS Indicator | Yes |
| Material | NYLON 6/6 |
| Operating Temperature Celcius Max | 85 °C |
| Operating Temperature Celcius Min | -40 °C |
| Rating - Minimum Tensile Strength lbs | 250 |
| Sub Brand | UNIRAP,CABLE TIE |
| Trade Name | UNIRAP™ |
| Type | Heavy Duty Releasable |
| UPC | 781810334850 |

Dimensions

| | |
|--------------------------------------|--------|
| Dimension - Bundle Diameter Max inch | 6 |
| Dimension - L Length Overall mm | 559 mm |

| | |
|---------------------------------|---------|
| Dimension - Length Overall inch | 22 in |
| Dimension - Width inch | 0.50 in |
| Dimension - Width mm | 13 mm |

Certifications And Compliance

| | |
|------------------------------------|-----|
| Buy American Compliant | Yes |
| Certification - 94V0 Rated | N |
| Certification - CSA Approved | No |
| Certification - ETL | No |
| Certification - UL Recognized | No |
| Certification - UV Rated | Yes |
| Certification - cULus | No |
| Standards - RoHS Compliance Status | CM |
| UL Listed | No |

Logistics

| | |
|-----------------------|-----|
| Carton Quantity | 500 |
| Minimum Pack Quantity | 25 |

Product Assets

[Catalogs - BURNDY Master Catalog - Full Line BURNDY Catalog](#)
[Catalogs - BURNDY Master Catalog - Section G - Wire Management](#)
[Interactive Catalog - BURNDY Full-Line Digital Catalog](#)
[Product Cross Section Image\(s\) - BUR_CT_UNIRAP_REL_CABLETIE_LineArt](#)
[Sales Drawings - 50034347](#)
[Specifications - CT250600RQ0](#)