




# CT250800RQ0, Cable Tie, 8" Max Bundle, 250 Lb Tensile, UV Black, Releasable

By Burndy

Catalog # [CT250800RQ0](#)

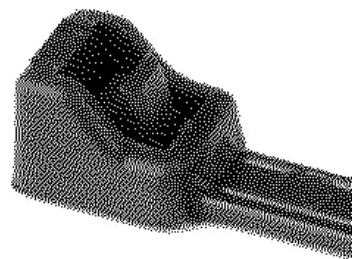

Nylon cable ties, Tensile strength-250 Lbs, Color- UV Black, 29.00"L, 0.50"W, 08.00" Bundle Dia.

## Features

Releaseable

## General

Catalog Number	CT250800RQ0
Color	Black
Material	NYLON 6/6
Operating Temperature Celcius Max	85 °C
Operating Temperature Celcius Min	-40 °C
Rating - Minimum Tensile Strength lbs	250
Trade Name	UNIRAP™
UPC	781810334874

## Dimensions

Dimension - Bundle Diameter Max inch	8
Dimension - L Length Overall mm	737 mm
Dimension - Length Overall inch	29 in
Dimension - Width inch	0.50 in
Dimension - Width mm	13 mm

## Certifications And Compliance

Certification - 94V0 Rated	N
Certification - CSA Approved	No
Certification - ETL	No
Certification - UL Recognized	No
Certification - UV Rated	Yes
Certification - cULus	No
Standards - RoHS Compliance Status	CM
UL Listed	No

## Logistics

Carton Quantity	1000
Minimum Pack Quantity	25
Packaging Type	Bag

## Product Assets

- [Catalogs - BURNDY Master Catalog - Full Line BURNDY Catalog](#)
- [Catalogs - BURNDY Master Catalog - Section G - Wire Management](#)
- [Interactive Catalog - BURNDY Full-Line Digital Catalog](#)
- [Product Cross Section Image\(s\) - BUR\\_CT\\_UNIRAP\\_REL\\_CABLETIE\\_LineArt](#)
- [Sales Drawings - 50034347](#)
- [Specifications - CT250800RQ0](#)