




# CT30125M, Cable Tie, 1.25" Max Bundle, 30 Lb Tensile, Natural

By Burndy  
Catalog # [CT30125M](#)

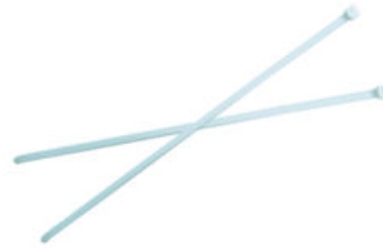

Natural Nylon 6/6 Cable Tie, 1.25" Max. Bundle Dia, 30 Lbs, 6" Long, 0.14" Wide.

## Features

Standard Cable Tie

## Application

For General Purpose

## General

Catalog Number	CT30125M
Color	Natural
EU RoHS Indicator	Yes
Material	NYLON 6/6
Military Specification	MS3367
Operating Temperature Celcius Max	85 °C
Operating Temperature Celcius Min	-40 °C
Rating - Minimum Tensile Strength lbs	30
Sub Brand	UNIRAP,CABLE TIE
Trade Name	UNIRAP™
Type	Intermediate
UPC	781810331910

## Dimensions

Dimension - Bundle Diameter Max inch	1.25
Dimension - L Length Overall mm	146 mm
Dimension - Length Overall inch	5.75 in
Dimension - Width inch	0.14 in
Dimension - Width mm	3.6 mm

## Certifications And Compliance

Certification - 94V0 Rated	No
Certification - CSA Approved	No
Certification - ETL	No
Certification - UL Recognized	No
Certification - UV Rated	No
Certification - cULus	Yes
Industry Standard(s)	Military Specified (Mil-Spec)
Military Spec Number	MS3367-5-9
Standards - Industry Standards Met	Military Specified (Mil-Spec)
Standards - RoHS Compliance Status	CM
UL Listed	No

## Logistics

Carton Quantity	5000
Minimum Pack Quantity	1000

## Product Assets

[Catalogs - Full Line BURNDY Catalog](#)  
[Catalogs - Section G - Wire Management](#)  
[Product Cross Section Image\(s\) - BUR\\_CT\\_UNIRAP\\_CABLE\\_TIE\\_LineArt](#)  
[Sales Drawings - 50080813](#)



A proud member of the Hubbell Family.

©2024 Hubbell Incorporated. All rights reserved.  
BRDY-CT30125M-SPEC-EN | REV 6/2024