




## CT40200C, Cable Tie, 2" Max Bundle, 40 Lb Tensile, Natural

By Burndy  
Catalog # [CT40200C](#)

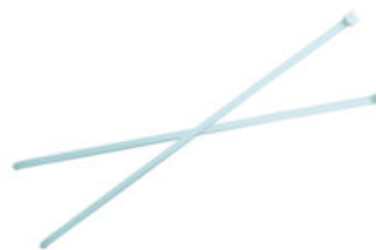

Natural Nylon 6/6 Cable Tie, 2" Max. Bundle Dia, 40 Lbs, 8.50" Long, 0.15" Wide.

### Features

Standard Cable Tie

### Application

For General Purpose

### General

Catalog Number	CT40200C
Color	Natural
EU RoHS Indicator	Yes
Material	NYLON 6/6
Operating Temperature Celcius Max	85 °C
Operating Temperature Celcius Min	-40 °C
Rating - Minimum Tensile Strength lbs	40
Sub Brand	UNIRAP,CABLE TIE
Tool Type	Intermediate
Trade Name	UNIRAP™
Type	Intermediate
UPC	781810331927

### Dimensions

Dimension - Bundle Diameter Max inch	2
Dimension - L Length Overall mm	225 mm
Dimension - Length Overall inch	8.87 in
Dimension - Width inch	0.14 in
Dimension - Width mm	4 mm

### Certifications And Compliance

Buy American Compliant	Yes
Certification - 94V0 Rated	N
Certification - CSA Approved	No
Certification - ETL	No
Certification - UL Recognized	No
Certification - UV Rated	No
Certification - cULus	No
Standards - RoHS Compliance	CM
Status	
UL Listed	Yes

### Logistics

Carton Quantity	1000
Minimum Pack Quantity	100

### Product Assets

[Catalogs - BURNDY Master Catalog - Full Line BURNDY Catalog](#)  
[Catalogs - BURNDY Master Catalog - Section G - Wire Management](#)  
[Interactive Catalog - BURNDY Full-Line Digital Catalog](#)  
[Product Cross Section Image\(s\) - BUR\\_CT\\_UNIRAP\\_CABLE\\_TIE\\_LineArt](#)  
[Sales Drawings - 50080813](#)  
[Specifications - CT40200C](#)