




CT50175CUG, Cable Tie, 50 Lb Tensile, Natural, Universal Grade

By Burndy
Catalog # CT50175CUG

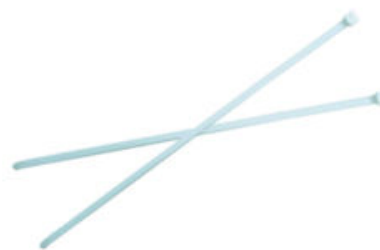

Universal Grade Cable Tie, 8 IN L, 0.18 IN W, Tensile Strength: 50 LB Minimum, Material: Nylon 6/6, Color: Natural.

Features

Standard Cable Tie

Application

For General Purpose

General

Catalog Number	CT50175CUG
Color	Natural
EU RoHS Indicator	Yes
Material	NYLON 6/6
Rating - Minimum Tensile Strength lbs	50
Sub Brand	UNIRAP,CABLE TIE
Tool Type	Standard
Trade Name	UNIRAP™
Type	UG, Standard
UPC	781810469071

Dimensions

Dimension - Bundle Diameter Max inch	1.75
Dimension - L Length Overall mm	199 mm
Dimension - Length Overall inch	7.83 in
Dimension - Width inch	0.18 in
Dimension - Width mm	4.6 mm

Certifications And Compliance

Buy American Compliant	No
Certification - CSA Approved	No
Certification - ETL	No
Certification - UL Recognized	Yes
Certification - UV Rated	No
Certification - cULus	No
Standards - RoHS Compliance	CM
Status	
UL Listed	No

Logistics

Carton Quantity	9000
Minimum Pack Quantity	100
Pallet Quantity	18000

Product Assets

- [Catalogs - BURNDY Master Catalog - Full Line BURNDY Catalog](#)
- [Catalogs - BURNDY Master Catalog - Section G - Wire Management](#)
- [Interactive Catalog - BURNDY Full-Line Digital Catalog](#)
- [Product Cross Section Image\(s\) - BUR_CT_UNIRAP_CABLE_TIE_LineArt](#)
- [Sales Drawings - 10092186](#)
- [Specifications - CT50175CUG](#)