


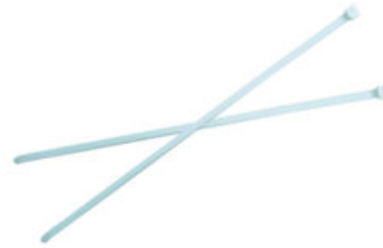

# CT50300CUG, Cable Tie, 50 Lb Tensile, Natural, Universal Grade

By Burndy  
Catalog # [CT50300CUG](#)

Universal Grade Cable Tie, 11.3 IN L, 0.18 IN W, Color: Natural,  
Tensile Strength: 50 LB Minimum, Material: Nylon 6/6.



## Features

Standard Cable Tie

## Application

For General Purpose

## General

Color	Natural
EU RoHS Indicator	Yes
Material	NYLON 6/6
Rating - Minimum Tensile Strength lbs	50
Sub Brand	UNIRAP,CABLE TIE
Tool Type	Standard
Trade Name	UNIRAP™
Type	UG, Standard
UPC	781810469101

## Dimensions

Dimension - Bundle Diameter Max inch	3
Dimension - L Length Overall mm	288 mm
Dimension - Length Overall inch	11.34 in
Dimension - Width inch	0.18 in
Dimension - Width mm	5 mm

## Certifications And Compliance

Certification - CSA Approved	No
Certification - ETL	No
Certification - UL Recognized	Yes
Certification - UV Rated	No
Certification - cULus	No
Standards - RoHS Compliance Status	CM
UL Listed	No

## Logistics

Carton Quantity	7000
Minimum Pack Quantity	100

## Product Assets

[Catalogs - Full Line BURNDY Catalog](#)  
[Product Cross Section Image\(s\) - BUR\\_CT\\_UNIRAP\\_CABLE\\_TIE\\_LineArt](#)  
[Sales Drawings - 10092186](#)



A proud member of the Hubbell Family.

©2024 Hubbell Incorporated. All rights reserved.  
BRDY-CT50300CUG-SPEC-EN | REV 5/2024