


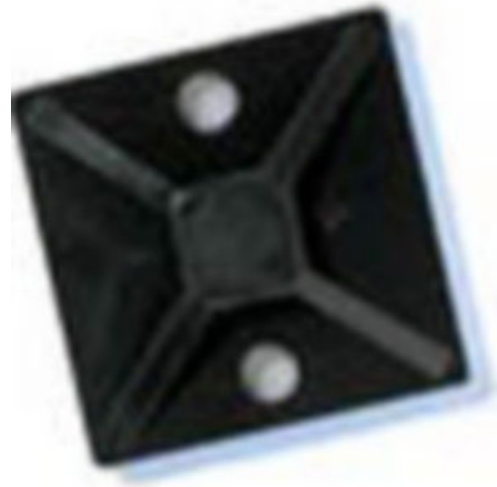

CTB075RA4CUG, Cable Tie Mounting Base, Rubber Adhesive, Natural

By Burndy
Catalog # [CTB075RA4CUG](#)

Nylon Cable tie mounting bases, Color:Natural, 0.75" L, 0.75" W, Max Tie Slot Width: 0.20", Tensile Strength: 9 Lbs.



Features

Cable Tie Base

General

Color	Natural
Material	NYLON 6/6
Mounting Method	Rubber adhesive
Type	Cable Tie Bases
UPC	781810499115

Dimensions

Dimension - B Length inch	0.74 in
Dimension - Width inch	0.74 in

Certifications And Compliance

Certification - CSA Approved	No
Certification - ETL	No
Certification - UL Recognized	Yes
Certification - UV Rated	No
Certification - cULus	No
Standards - RoHS Compliance Status	CM
UL Listed	No

Logistics

Carton Quantity	13000
Minimum Pack Quantity	100

Product Assets

- [3D Models - CTB075RA4CUG_MODEL-PDF](#)
- [3D Models - CTB075RA4CUG_MODEL-STEP](#)
- [3D Models - CTB075RA4CUG_MODEL-IGES](#)
- [Catalogs - Full Line BURNDY Catalog](#)
- [Product Cross Section Image\(s\) - BUR_CTB_MOUNTING_BASE_LineArt](#)
- [Sales Drawings - 30003529](#)



A proud member of the Hubbell Family.

©2024 Hubbell Incorporated. All rights reserved.
BRDY-CTB075RA4CUG-SPEC-EN | REV 5/2024