


FLN1425X03D, Nylon Flag-Style Quick Disconnect For 16 - 14 AWG (.25 x .03)

By Burndy
Catalog # [FLN1425X03D](#)

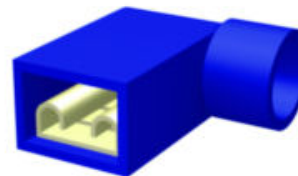

Nylon Flag-Style Quick Disconnect For 16 - 14 AWG (.25 x .03).

Features

- Flag-style female quick disconnects provide quick, reliable, snap-together interconnections without the use of tools
- Side entrance chamfer permits connections of 90° without bending the wire
- Dimpled female socket detent ensures firm grip

Application

Female Disconnect

General

Catalog Number	FLN1425X03D
Connector Type	Flag Female Quick Disconnect
EU RoHS Indicator	Yes
Insulation	Y
Insulation Type	Nylon
Material	Brass
Plated	Y
Plating Type	Tin
Sub Brand	HYDENT
Trade Name	FINGRIP™
Type	Disconnect Connectors
UPC	781810525623
UPC 12 Digit	7818105256233

Dimensions

Dimension - B Length inch	0.40 in
Dimension - Strip Length inch	3/8 in
Dimension - Width inch	0.25 in
Dimension - Width mm	6 mm

Conductor Related

Conductor Range	#16 AWG to #14 AWG
Conductor Size	16 - 14 AWG
Conductor Type	<ul style="list-style-type: none">• CU C Solid-Size• CU C Str-Size

Certifications And Compliance

Buy American Compliant	No
Certification - CSA Approved	No
Certification - ETL	No
Certification - UL Recognized	No
Certification - cULus	No
Standards - RoHS Compliance	CM
Status	
UL Listed	No

Logistics

Carton Quantity	600
Minimum Pack Quantity	50
Pallet Quantity	99999

Product Assets

[Catalogs - BURNDY Master Catalog - Full Line BURNDY Catalog](#)
[Catalogs - BURNDY Master Catalog - Section B - Small Compression](#)
[Customer Notices - Prop 65 Notice](#)
[Interactive Catalog - BURNDY Full-Line Digital Catalog](#)
[Sales Drawings - 30009427](#)
[Specifications - FLN1425X03D](#)