


## FLN1825X03D, Nylon Flag-Style Quick Disconnect For 22 - 18 AWG (.25 x .03)

By Burndy  
Catalog # [FLN1825X03D](#)

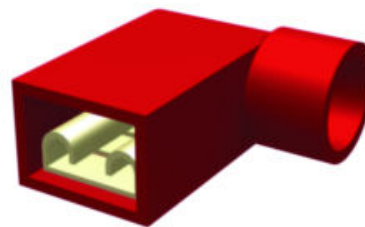

Nylon Flag-Style Quick Disconnect For 22 - 18 AWG (.25 x .03).

### Features

- Flag-style female quick disconnects provide quick, reliable, snap-together interconnections without the use of tools
- Side entrance chamfer permits connections of 90° without bending the wire
- Dimpled female socket detent ensures firm grip

### General

Catalog Number	FLN1825X03D
Connector Type	Flag Female Quick Disconnect
Insulation	Y
Insulation Type	Nylon
Material	Brass
Plated	Y
Plating Type	Tin
Trade Name	FINGRIP™
Type	Disconnect Connectors
UPC	781810563243
UPC 12 Digit	7818105632433

### Dimensions

Dimension - B Length inch	0.40 in
Dimension - Strip Length inch	3/8 in
Dimension - Width inch	0.25 in
Dimension - Width mm	6 mm

### Conductor Related

Conductor Range	#22 AWG to #18 AWG
Conductor Size	22 - 18 AWG
Conductor Type	CU C Str-Size

### Certifications And Compliance

Certification - CSA Approved	No
Certification - ETL	No
Certification - UL Recognized	No
Certification - cULus	Yes
Standards - Industry Standards Met	UL310
Standards - RoHS Compliance	CM
Status	
UL Listed	No

### Logistics

Carton Quantity	600
Minimum Pack Quantity	50
Pallet Quantity	99999

### Product Assets

- [3D Models - FLN1825X03D\\_MODEL-STEP](#)
- [3D Models - FLN1825X03D\\_MODEL-PDF](#)
- [3D Models - FLN1825X03D\\_MODEL-IGES](#)
- [Catalogs - BURNDY Master Catalog - Full Line BURNDY Catalog](#)
- [Catalogs - BURNDY Master Catalog - Section B - Small Compression](#)
- [Customer Notices - Prop 65 Notice](#)
- [Interactive Catalog - BURNDY Full-Line Digital Catalog](#)
- [Sales Drawings - 30009427](#)
- [Specifications - FLN1825X03D](#)